




Koolance high quality, dual ball-bearing fan.


- Dimensions: 120x120x25mm
- Type: Dual Ball-Bearing
- Connector: 3-pin (3-wire with tachometer)
- Rated Voltage: 12VDC
- Current: 0.28A
- Speed: 2600RPM (max)
- Static Pressure: 5.4mm-H2O
- Airflow: 107.6CFM (max)
- Noise: 32.80dBA (max)
- 50k hours MTBF

General	
Weight	0.40 lb (0.18 kg)
Noise (dBA)	32.8
Fans	
Airflow (CFM)	107.6
Current (A)	0.28
Size (mm)	120 x 120 x 25
Speed (RPM)	2600
Static Pressure (mm-H2O)	5.4
Tachometer	yes
Type	Dual Ball Bearing
Voltage	12 VDC

P&Q Curve:

FAN-12025HBK

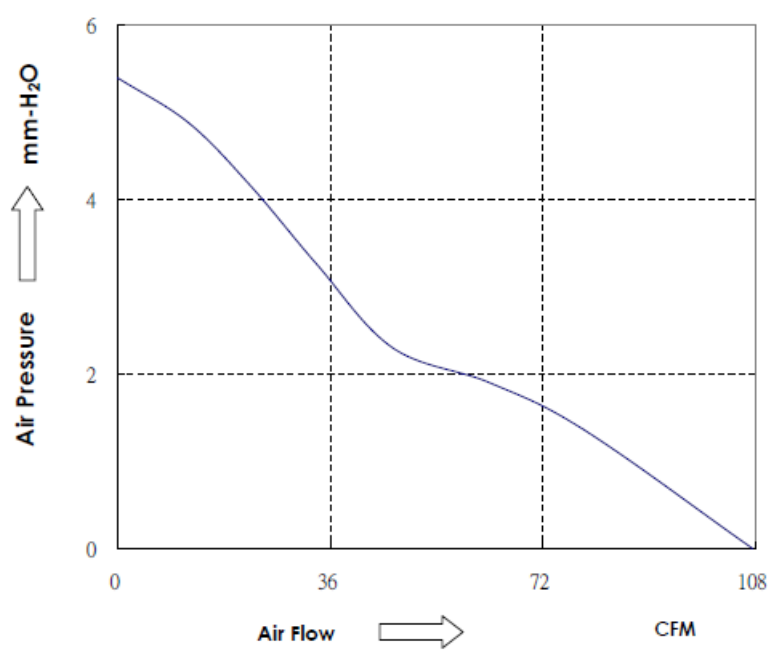

NO.		DESCRIPTION		PART NO.		QTY.	REMARKS
 <b>KOOLANCE®</b>				UNIT	MM	ITEM      Fan	
DRAWN BY		BY	BY	APPRO BY	SCALE	N/S	TITLE
DATE					3RD ANGLE		
AUG.10.2021		S.J.LEE		J.S.PARK	KK CODE NO.		DRAWING NO.
					FAN-12025HBK		REV
							—