




www.koolance.com

Specifications Sheet

Generated: 2024-04-25

P/N: FAN-22030HLED

Fan, 220x30mm, 40.5CFM, Blue LED

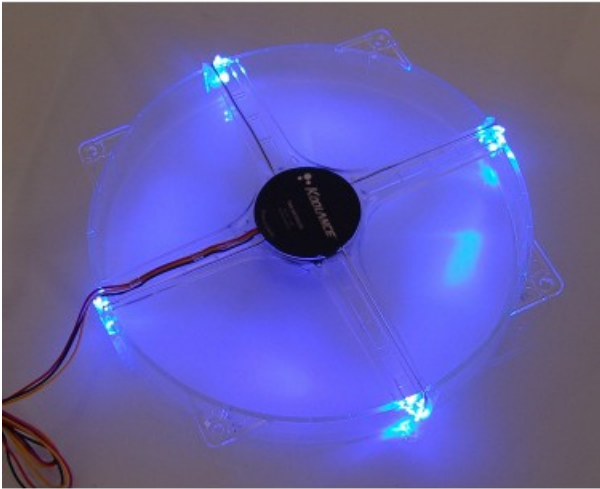

Koolance high quality, dual ball-bearing fan with blue LEDs.

- Dimensions: 220x220x30mm
- Type: Dual Ball-Bearing
- Connector: 3-pin (3-wire with tachometer)
- Rated Voltage: 12VDC
- Current: 0.34A
- Speed: 800RPM (max)
- Static Pressure: 0.86mm-H2O
- Airflow: 40.5CFM (max)
- Noise: 34.7dBA (max)
- 50k hours MTBF

General	
Weight	0.75 lb (0.34 kg)
Noise (dBA)	34.7
Fans	
Airflow (CFM)	40.5
Current (A)	0.34
Size (mm)	220 x 220 x 30
Speed (RPM)	800
Static Pressure (mm-H2O)	0.86
Tachometer	yes
Type	Dual Ball Bearing
Voltage	12 VDC