


# 1 KOOLANCE KIT-EHX1020 Assembly Guide v 1.0

Place the radiator with nozzle sockets pointed downward. Mounting posts will be screwed into all 12 fan hole positions.


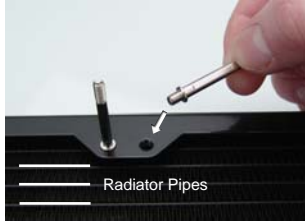


Insert and tighten each mounting post into the 12 fan hole positions shown above. The shortest thread goes into the radiator.

If necessary, use a small wrench or pliers to tighten the posts. Be careful not to damage any of the radiator pipes.

Place all 3 fans onto the mounting posts with labels facing down (airflow moving down into the radiator).

For cleanliness, keep all fan cables facing the same direction to one side of the radiator.

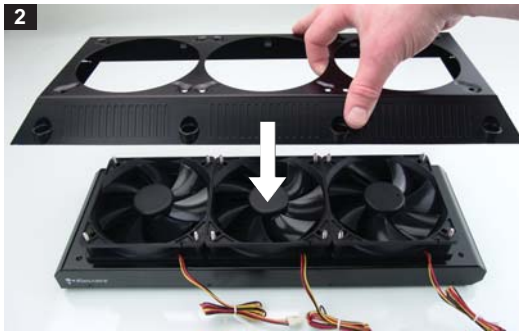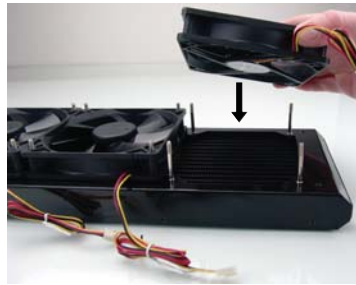

Place the shroud onto the posts above the fans.



Place the 3 fan grills onto the posts above the shroud.



Tighten a thumb nut onto all 12 mounting posts.

# 3

Connect all 3 fans to the wiring harness. The harness accepts up to 4 fans, so one female plug will remain unused.

Use the 3-wire plug from the harness if you wish to pass fan RPM tachometry. This can only be done for 1 of the 3 fans (the rest use a 2-wire connection).



KIT-EHX1020 includes 8 metal bushings and self-tapping screws to assist with mounting. These are inserted into the outer plastic receptacles on the fan shroud.

That completes assembly of this product. For the hole cutout stencil diagram to mount this product, please visit the product's website by typing "KIT-EHX1020" into the search box on [www.koolance.com](http://www.koolance.com)