



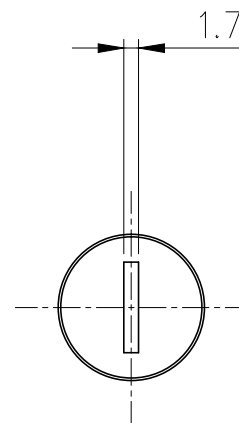


Fitting socket screw plug and gasket for G 1/4 BSPP
Koolance threaded connections. Nickel-plated brass.

General	
Weight	0.03 lb (0.01 kg)
Fitting Thread	G 1/4 BSPP
Max Pressure Tolerance @ 25° C	15kgf/cm2 (213.4psi)
Max Temperature Tolerance	120° C (248° F)
Wetted Materials	Brass, Nickel Plating, EPDM

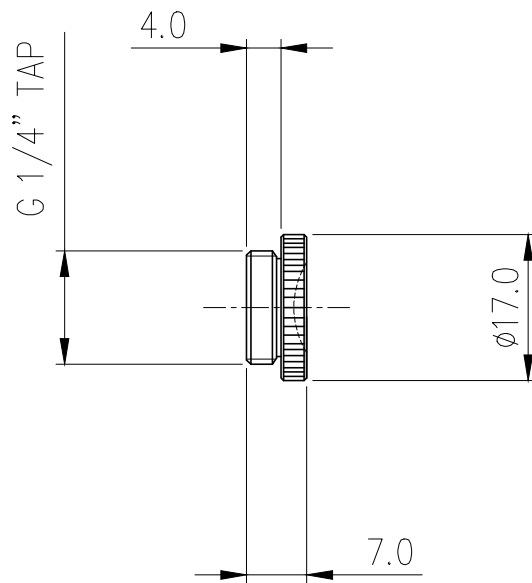

NO.		DESCRIPTION			MATER'L		QUANTITY		REMARKS	
					UNIT	MM	PART NO. SCR-CP003PG(-BK)			
					SCALE	N/S	TITLE			
DATE		BY	BY	BY	APPRO BY	3RD ANGLE		Ass'y		
05/02/2017		S.J.LEE				DWG. NO.		ITEM		