



P/N: TNK-CNT50T70


Reservoir Thread Adapter, Acetal (60mm to 80mm)



Male to male threaded adapter ring for combining Koolance [60mm OD reservoir components](#) with [80mm OD reservoir components](#). Acetal with dual EPDM O-rings.

General	
Weight	0.08 lb (0.04 kg)
Max Pressure Tolerance @ 25° C	2kgf/cm2 (28.5psi)
Max Temperature Tolerance	80° C (176° F)

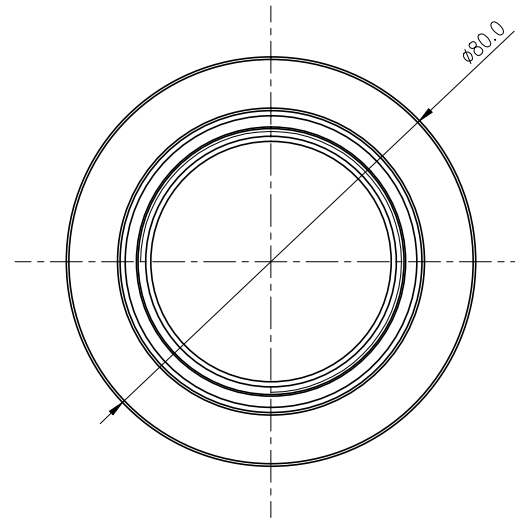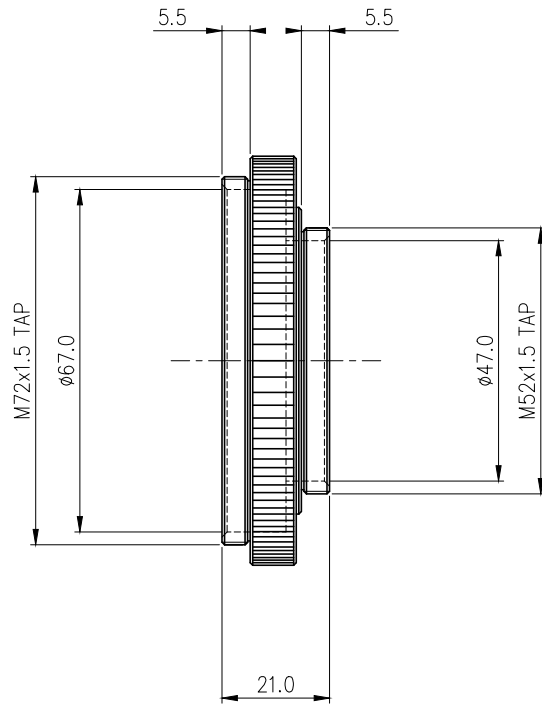

NO.		DESCRIPTION			MATER'L		QUANTITY	REMARKS
					UNIT	MM	PART NO. TNK – CNT50T70	
					SCALE	N/S	TITLE	
DATE		BY	BY	BY	APPRO BY	Ass'y		
05/09/2017		S.J.LEE				3RD ANGLE		
						DWG. NO.		ITEM