




The RP-985 incorporates Koolance's [PMP-300](#) pump. Designed to fit a single 5.25" (CD) bay, it utilizes the same reservoir, front LED display, and rear G 1/4 BSPP (parallel) thread fitting sockets.


Features:

- Fits a single 5.25" CD bay
- Adjusts radiator fan speeds automatically, or with 10 manual levels
- Manual pump speed adjustment
- Variable temperature alarms on 3 independent sensors
- Auto-cycle or static display of all connected temperature sensors
- Variable safety shutdown temperature
- Front and top reservoir blue LED lighting
- Top refill plug

IMPORTANT NOTE: The pump should never be run dry. Always test this product with coolant.

| General | |
|--------------------------------|--------------------|
| Weight | 2.20 lb (1.00 kg) |
| Fitting Thread | G 1/4 BSPP |
| Max Pressure Tolerance @ 25° C | 1kgf/cm2 (14.2psi) |
| Max Temperature Tolerance | 60° C (140° F) |
| Reservoirs | |
| Capacity | 237mL (8 fl oz) |
| Display Type | LED |
| Pump | PMP-300 @ 12V |
| Temperature Sensors | 10K Thermistors |

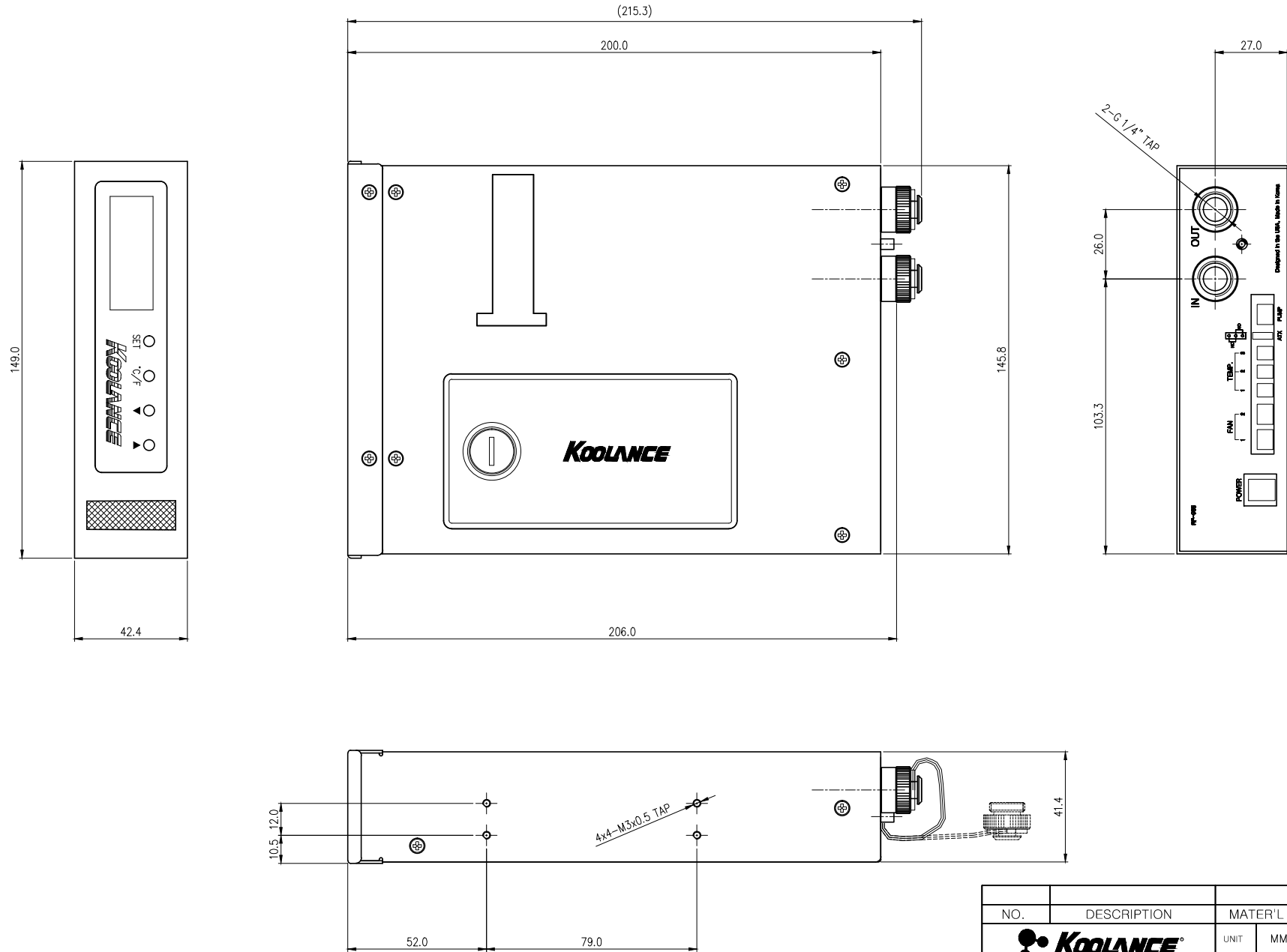

| | | | | | | | | |
|---|---------|-------------|----|----------|----------|-----|-----------------|---------|
| | | | | | | | | |
| NO. | | DESCRIPTION | | | MATER'L | | QUANTITY | REMARKS |
|  | | | | | UNIT | MM | PART NO. RP-985 | |
| | | | | | SCALE | N/S | TITLE | |
| | BY | BY | BY | APPRO BY | Ass'y | | | |
| DATE | | | | | | | | |
| 05/02/2017 | S.J.LEE | | | | DWG. NO. | | ITEM | |
| | | | | | | | | |