




P/N: ADT-DXG90S-BK


**Fitting Single, *Black* Swiveling 90-Degree
(Low Profile), G 1/4 BSPP**



Koolance low profile swiveling G 1/4 BSPP socket fitting.
Each segment rotates for a maximum 90-degree bend.

General	
Weight	0.09 lb (0.04 kg)
Fitting Thread	G 1/4 BSPP
Max Pressure Tolerance @ 25°C	8kgf/cm2 (113.8psi)
Max Temperature Tolerance	100°C (212°F)
Wetted Materials	Brass, EPDM

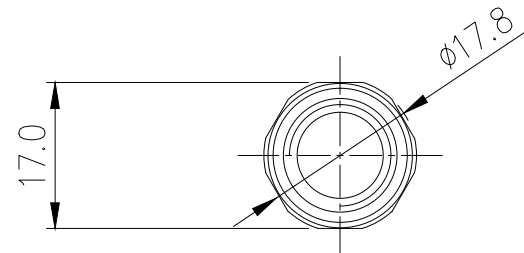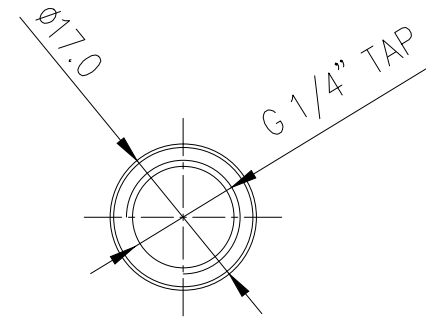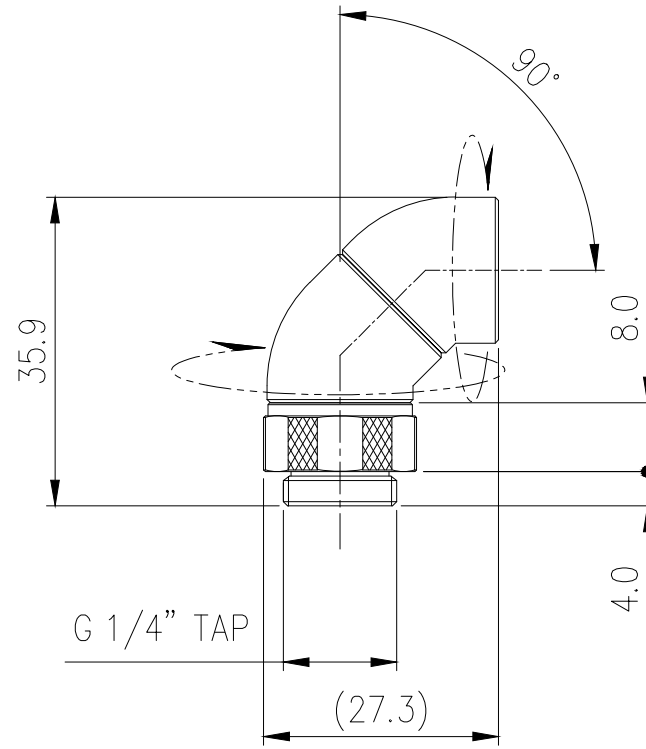

NO.		DESCRIPTION			MATER'L		QUANTITY		REMARKS	
					UNIT	MM	APPAR		ADT-DXG90S(-BK)	
		BY	BY	BY	APPRO	SCALE	N/S	TITLE Ass'y		
DATE					BY	3RD ANGLE				
JUN.15.2022		S.J.LEE				CODE NO.		DWG. NO.		