


Coolant Temperature Sensor, Brass, K-Type
Thermocouple



Coolant K-type thermocouple temperature sensor with fitting body. This product is designed to be placed inline on any hose. Simply choose G 1/4 BSPP threaded fittings for the desired hose diameter. Wire length = 30" (76cm). Accuracy = $\pm 1.5^{\circ}\text{C}$, temperature range = -40 to 120°C (-40 to 248°F).

General	
Weight	0.21 lb (0.10 kg)
Fitting Thread	G 1/4 BSPP
Max Temperature Tolerance	120°C (248°F)
Wetted Materials	Nickel-Plated Brass, Stainless Steel, EPDM

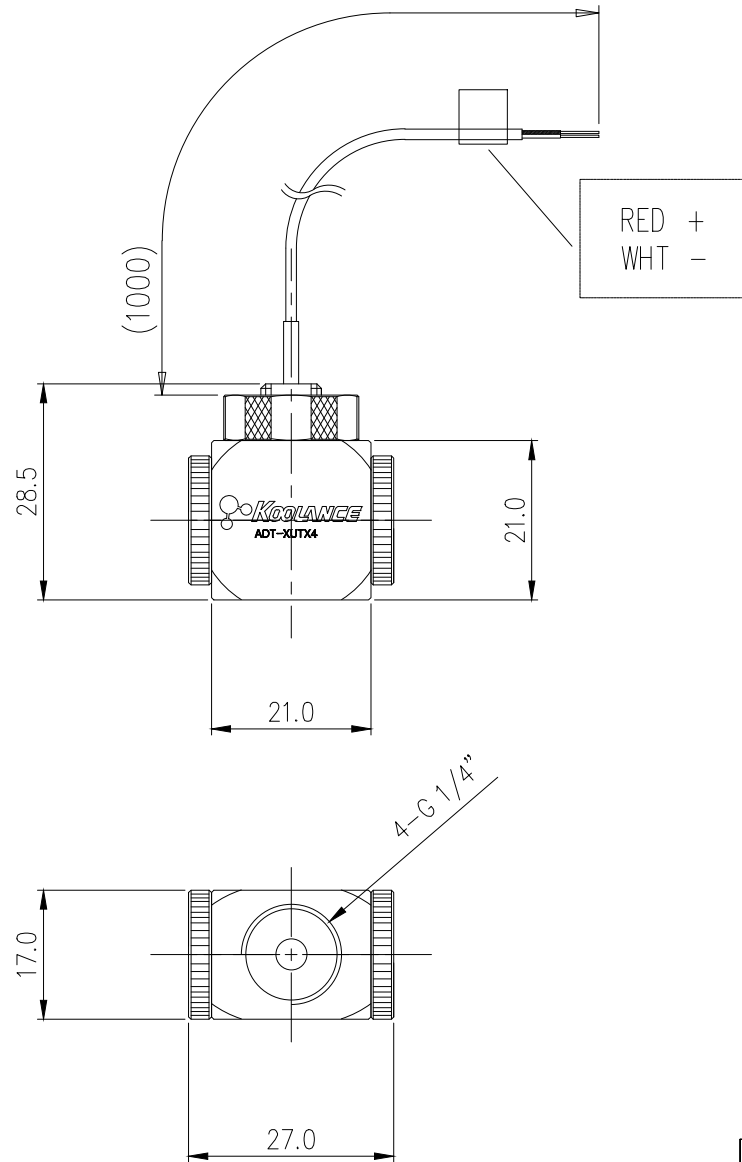

NO.	DESCRIPTION				MATER'L		QUANTITY	REMARKS
	KOOLANCE				UNIT	MM	ITEM	SEN-TCK01B
	BY	BY	BY	APPRO BY	SCALE	N/S	TITLE	
DATE					3RD ANGLE		Ass'y	
APR.05.2021	S.J.LEE				CODE NO.		DWG. NO.	PAGE