


Coolant Temperature Sensor, Brass, K-Type Thermocouple



Coolant K-type thermocouple temperature sensor with fitting body. This product is designed to be placed inline on any hose. Simply choose G 1/4 BSPP threaded fittings for the desired hose diameter. Wire length = 30" (76cm).

| General         |  |
|-----------------|--|
| Weight          | 0.21 lb (0.10 kg)                          |
| Fitting Thread  | G 1/4 BSPP                                 |
| Materials       | Nickel-Plated Brass, Stainless Steel, EPDM |
| Max Temperature | 120° C (248° F)                            |

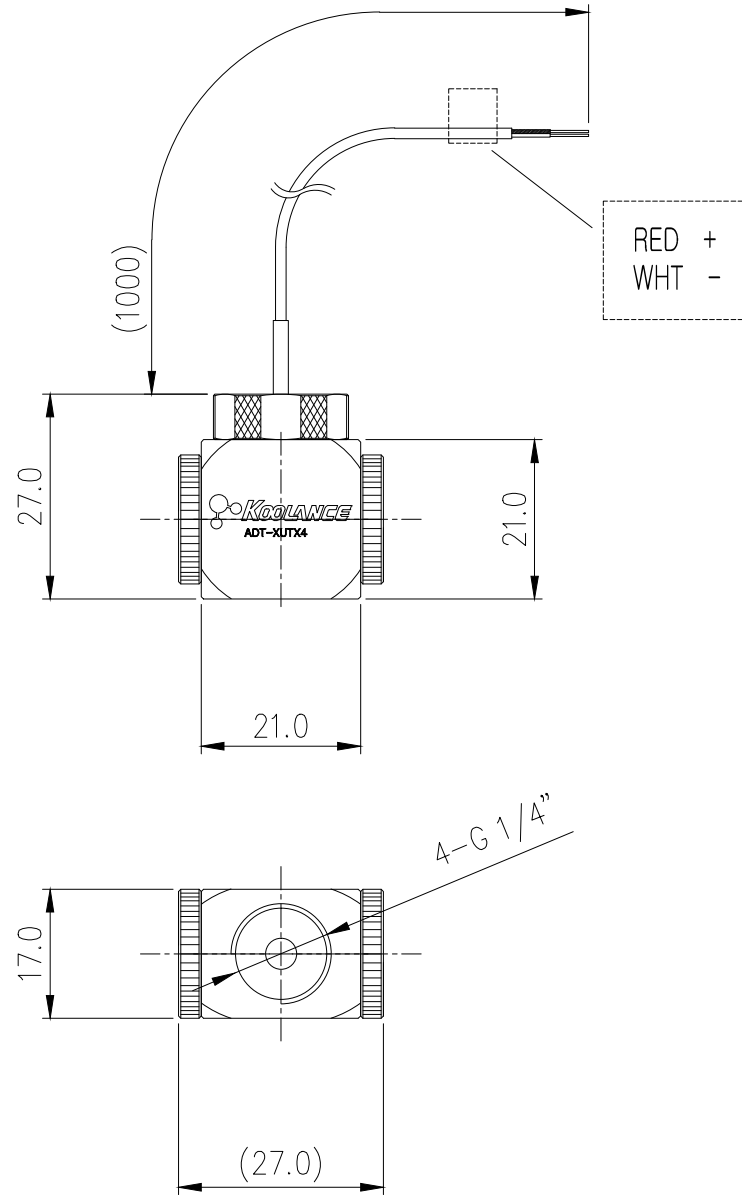

| NO.  | DESCRIPTION     | MATER'L |     | QUANTITY  | REMARKS    |
|------|-----------------|---------|-----|-----------|------------|
|      | <b>KOOLANCE</b> | UNIT    | MM  | ITEM      | SEN-TCK01B |
|      |                 | SCALE   | N/S | TITLE     |            |
| DATE | BY              | BY      | BY  | APPRO     | BY         |
|      | S.J.LEE         |         |     | 3RD ANGLE |            |
|      |                 |         |     | CODE NO.  | DWG. NO.   |
|      |                 |         |     |           | PAGE       |