

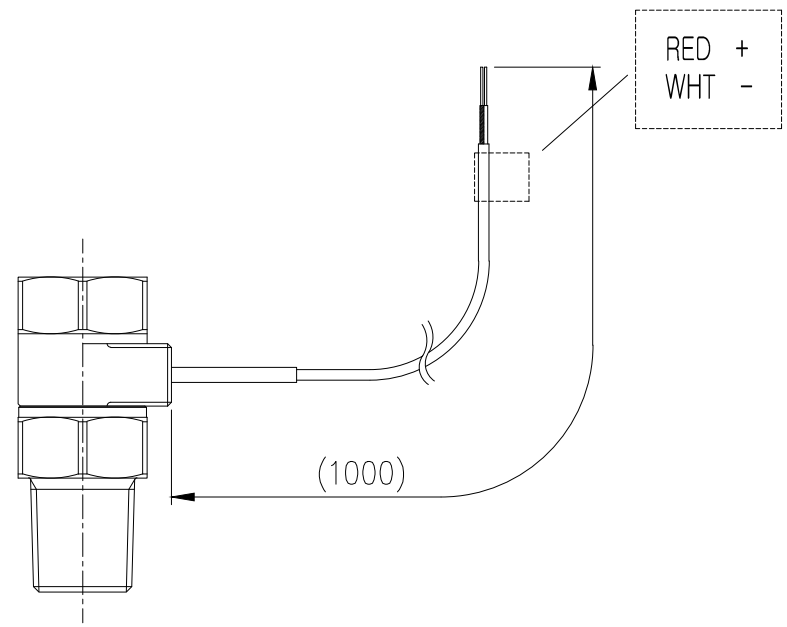


Coolant Temperature Sensor Inline, Male/Female Threads, K-Type Thermocouple

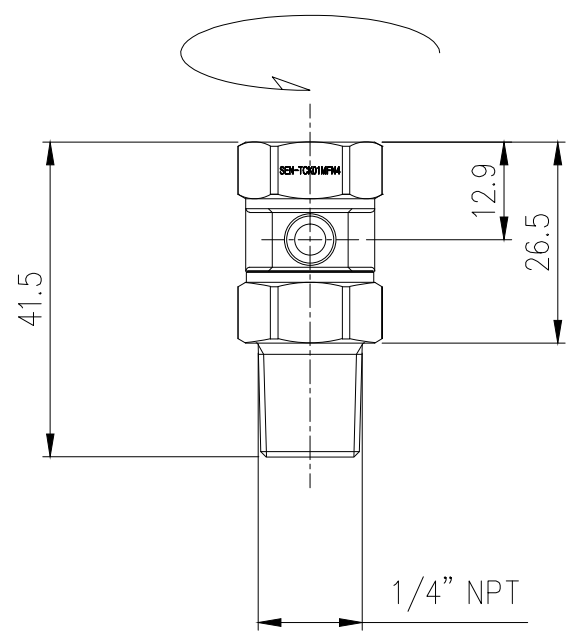

Coolant thermocouple temperature sensor within a swiveling brass body. Male and female NPT 1/4" threads are provided on either end. Wire length = 30" (76cm). Accuracy = +/- 1.5°C, temperature range = -40 to 120°C (-40 to 248°F).

General	
Weight	0.30 lb (0.14 kg)
Fitting Thread	NPT 1/4
Max Pressure Tolerance @ 25°C	10 kgf/cm ²
Wetted Materials	Nickel-Plated Brass, EPDM

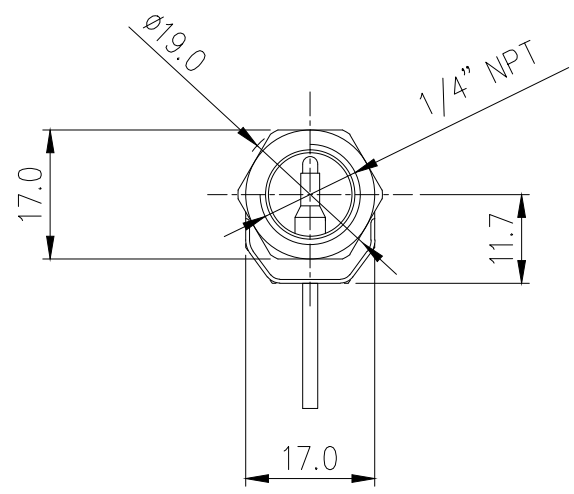

NO.	DESCRIPTION	MATER'L		QUANTITY	REMARKS
	KOOLANCE	UNIT	MM	ITEM	SEN-TCK01MFN4
		SCALE	N/S	TITLE	
DATE	BY	BY	BY	APPRO	BY
	S.J.LEE			3RD ANGLE	
		CODE NO.		DWG. NO.	PAGE

Ass'y