



www.koolance.com

Specifications Sheet

Generated: 2024-04-17




P/N: SEN-TCK01MFN4


Coolant Temperature Sensor Inline,
Male/Female Threads, K-Type Thermocouple



Coolant thermocouple temperature sensor within a swiveling brass body. Male and female NPT 1/4" threads are provided on either end. Wire length = 30" (76cm). Accuracy = +/- 1.5° C, temperature range = -40 to 120° C (-40 to 248° F).

General	
Weight	0.30 lb (0.14 kg)
Fitting Thread	NPT 1/4
Wetted Materials	Nickel-Plated Brass, EPDM

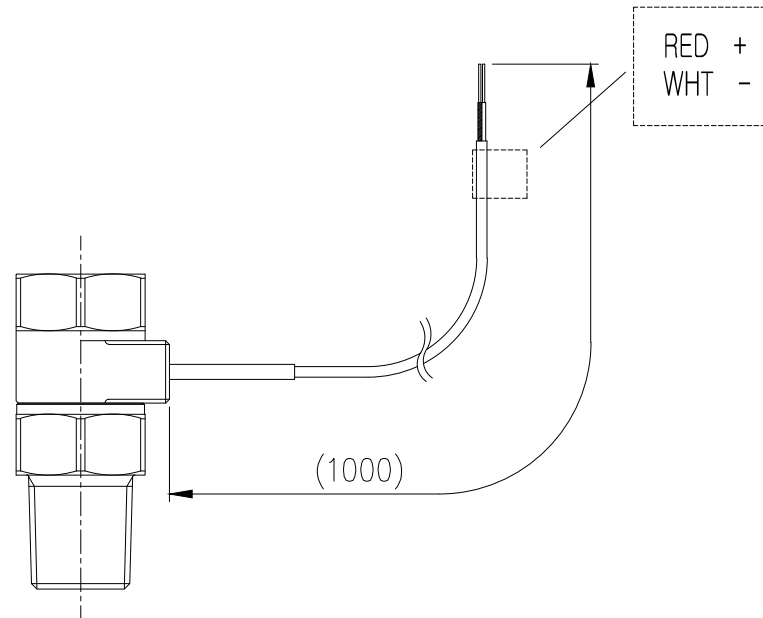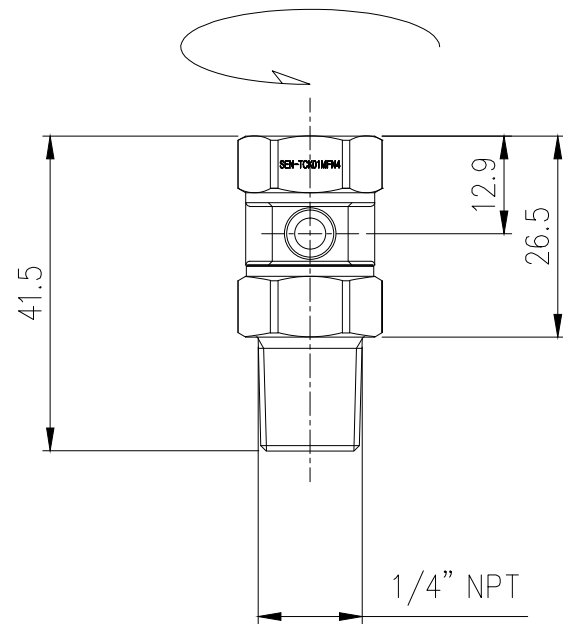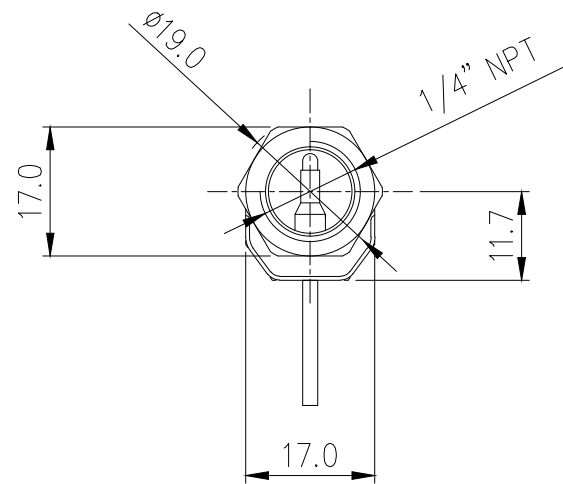

NO.		DESCRIPTION		MATER'L		QUANTITY	REMARKS
		UNIT		MM		ITEM	SEN-TCK01MFN4
				SCALE		N/S	TITLE
DATE		BY	BY	BY	BY	3RD ANGLE	
S.J.LEE						CODE NO.	
						DWG. NO.	
						PAGE	