




**Coolant Temperature Sensor Inline,
Male/Female Threads, K-Type Thermocouple**

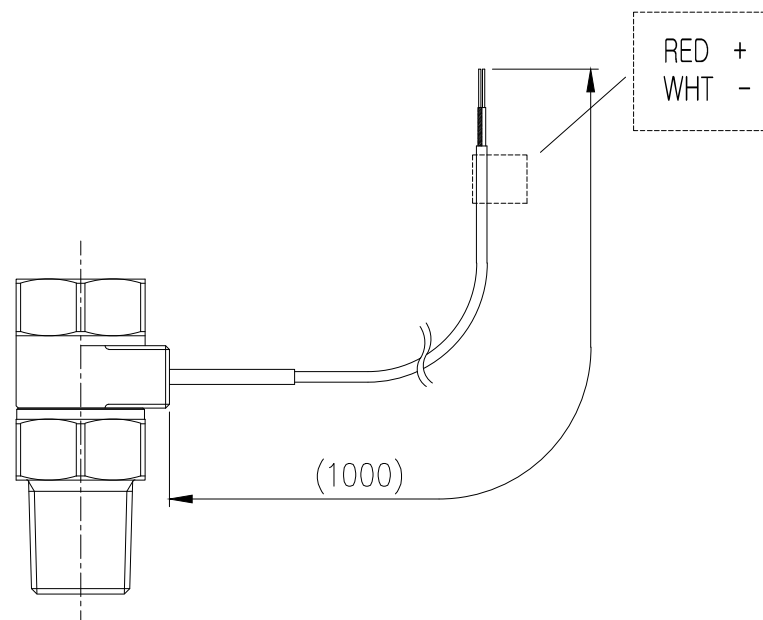

Coolant thermocouple temperature sensor within a swiveling brass body. Male and female NPT 1/4" threads are provided on either end. Wire length = 30" (76cm). Accuracy = +/- 1.5° C, temperature range = -40 to 120° C (-40 to 248° F).

General	
Weight	0.30 lb (0.14 kg)
Fitting Thread	NPT 1/4
Max Pressure Tolerance @ 25° C	10 kgf/cm2
Wetted Materials	Nickel-Plated Brass, EPDM

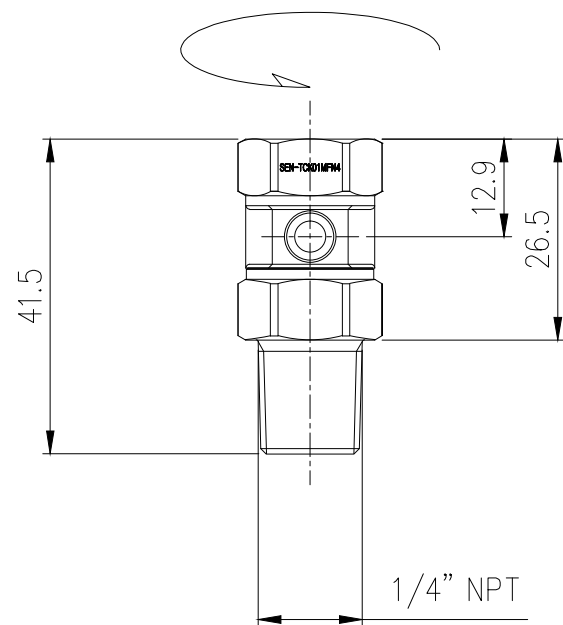

NO.		DESCRIPTION			MATER'L		QUANTITY	REMARKS
 KOOLANCE®					UNIT	MM	ITEM SEN-TCK01MFN4	
					SCALE	N/S	TITLE	
DATE		BY	BY	BY	APPRO	BY	Ass'y	
					3RD ANGLE			
S.J.LEE					CODE NO.		DWG. NO.	PAGE