


Coolant Temperature Sensor Plug, K-Type Thermocouple



Coolant K-type thermocouple sensor, compatible with Koolance EXC and ALX series systems. Sensor fitting is G 1/4 BSPP (parallel) threaded. Wire length = 38" (965mm). Accuracy = $\pm 1.5^{\circ}\text{C}$, temperature range = -40 to 120°C (-40 to 248°F).

General	
Weight	0.04 lb (0.02 kg)
Fitting Thread	G 1/4 BSPP
Max Temperature Tolerance	120°C (248°F)
Wetted Materials	Nickel-Plated Brass, Stainless Steel, EPDM

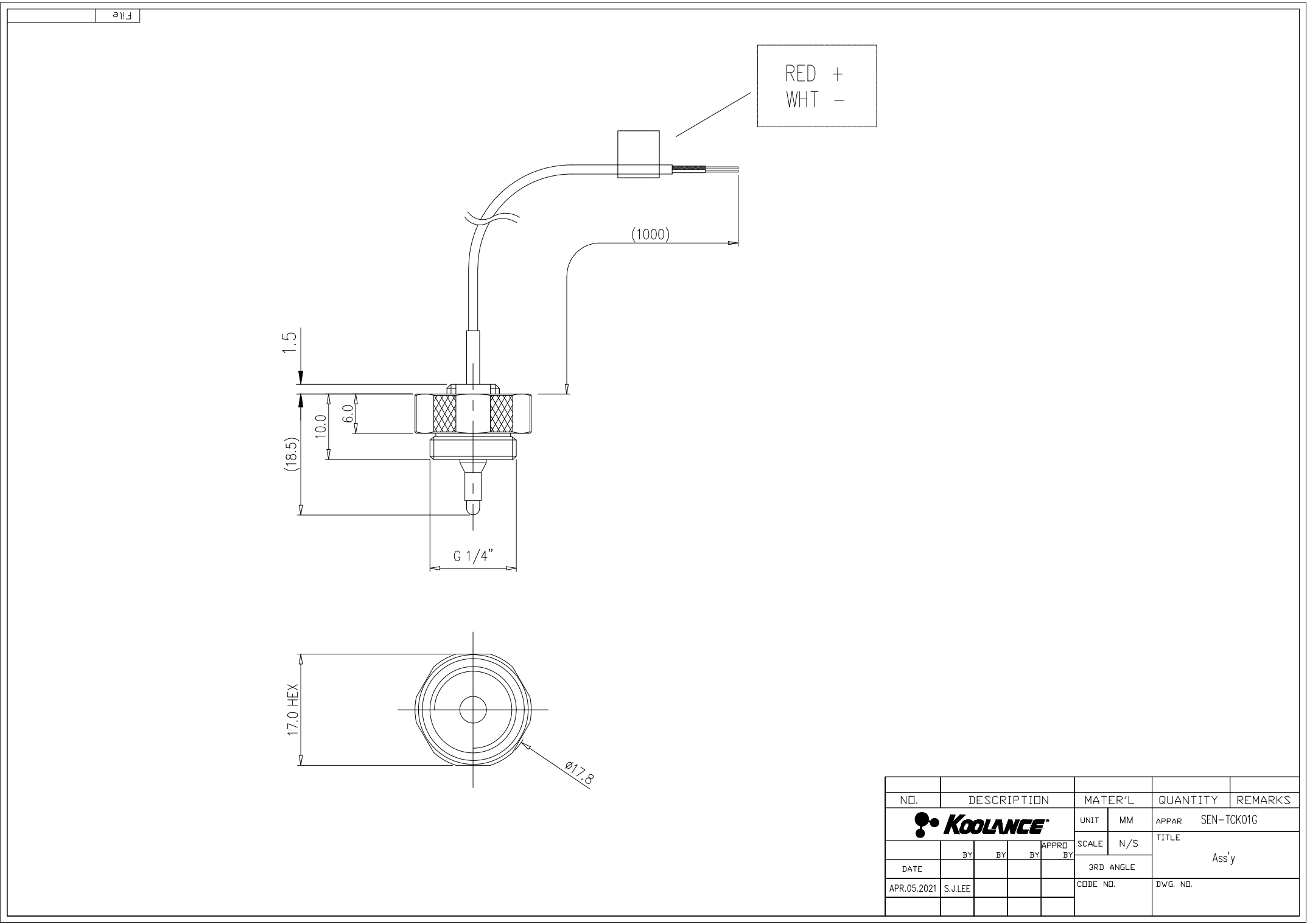

RED +
WHT -

(1000)

1.5

(18.5)

10.0

6.0

G 1/4"

17.0 HEX

17.8



UNIT MM APPAR SEN-TCK01G

SCALE N/S TITLE Ass'y

3RD ANGLE

CODE NO. DWG. NO.