



www.koolance.com

Specifications Sheet

Generated: 2024-04-25


P/N: SEN-TCK01G


Coolant Temperature Sensor Plug, K-Type Thermocouple



Coolant K-type thermocouple sensor, compatible with Koolance EXC and ALX series systems. Sensor fitting is G 1/4 BSPP (parallel) threaded. Wire length = 38" (965mm). Accuracy = +/-1.5°C, temperature range = -40 to 120°C (-40 to 248°F).

General	
Weight	0.04 lb (0.02 kg)
Fitting Thread	G 1/4 BSPP
Max Temperature Tolerance	120 °C (248 °F)
Wetted Materials	Nickel-Plated Brass, Stainless Steel, EPDM

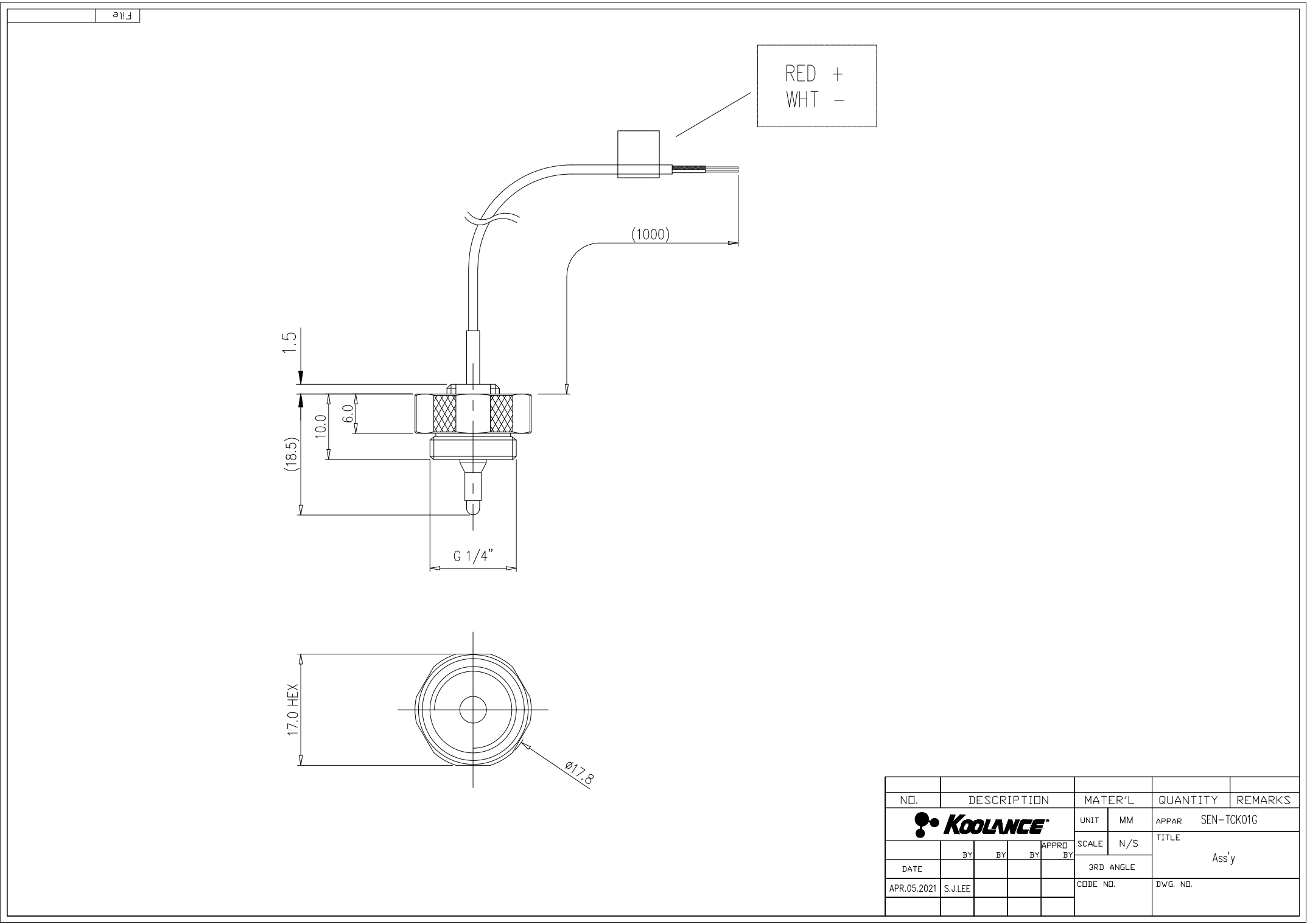

NO.	DESCRIPTION					MATER'L		QUANTITY		REMARKS	
						UNIT	MM	APPAR	SEN-TCK01G		
	BY	BY	BY	APPRO	BY	SCALE	N/S	TITLE			
DATE						3RD ANGLE		Ass'y			
APR.05.2021	S.J.LEE					CODE NO.		DWG. NO.			