


Coolant Temperature Sensor Plug, K-Type
Thermocouple



Coolant K-type thermocouple sensor, compatible with Koolance EXC and ALX series systems. Sensor fitting is G 1/4 BSPP (parallel) threaded. Wire length = 38" (965mm). Accuracy = +/-1.5°C, temperature range = -40 to 120°C (-40 to 248°F).

| General | |
|-------------------------------|--|
| Weight | 0.04 lb (0.02 kg) |
| Fitting Thread | G 1/4 BSPP |
| Materials | Nickel-Plated Brass, Stainless Steel, EPDM |
| Max Temp. Operating Tolerance | 120°C (248°F) |

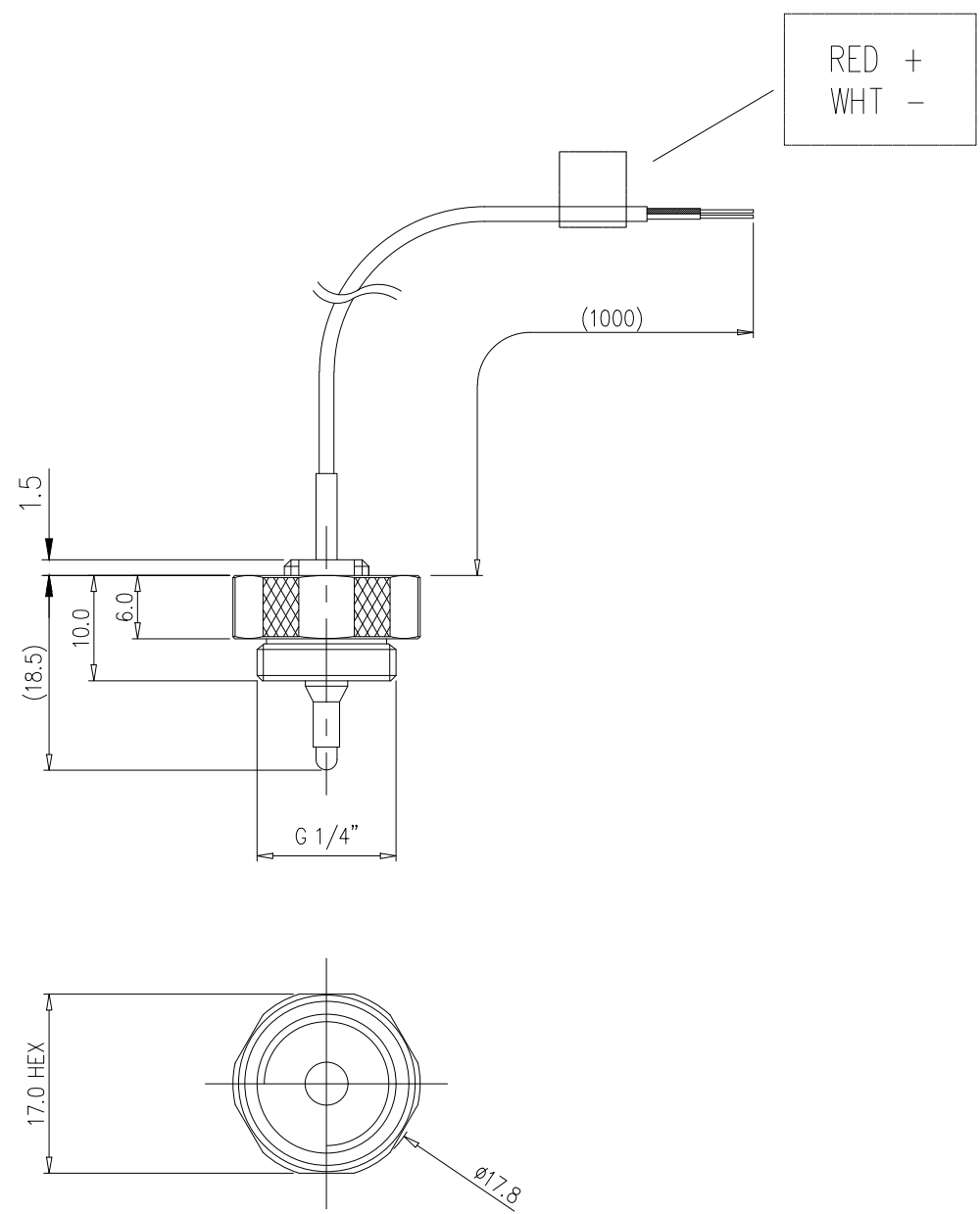

| NO. | DESCRIPTION | MATER'L | | QUANTITY | REMARKS |
|-------------|-----------------|---------|----------|-----------|------------|
| | KOOLANCE | UNIT | MM | APPAR | SEN-TCK01G |
| | | SCALE | N/S | TITLE | |
| DATE | BY | BY | APPRO BY | 3RD ANGLE | |
| APR.05.2021 | S.J.LEE | | | CODE NO. | DWG. NO. |
| | | | | | Ass'y |