


## Dual VID Connector, Adjustable 2-3 Slot Spacing




Adjustable direct connection fitting for supported Koolance VID coolers in series or parallel. CNT-VDA34 is for SLI or CrossFire setups that span four to five card slots (two to three in between are bypassed). Koolance VID water blocks occupy the same slot as the video card. See [this page](#) for more details.

G 1/4 BSPP threading, nickel-plated brass with compression fittings and gaskets. Will work with any hose diameter going in and out of the Koolance video coolers. To adjust, loosen the threaded center nut, slide apart, and re-tighten. Do not adjust sliding fittings beyond the safety line, marked "MAX".

General	
Weight	0.11 lb (0.05 kg)
Fitting Thread	G 1/4 BSPP
Max Pressure Tolerance @ 25° C	5kgf/cm2 (71.1psi)
Max Temperature Tolerance	100° C (212° F)

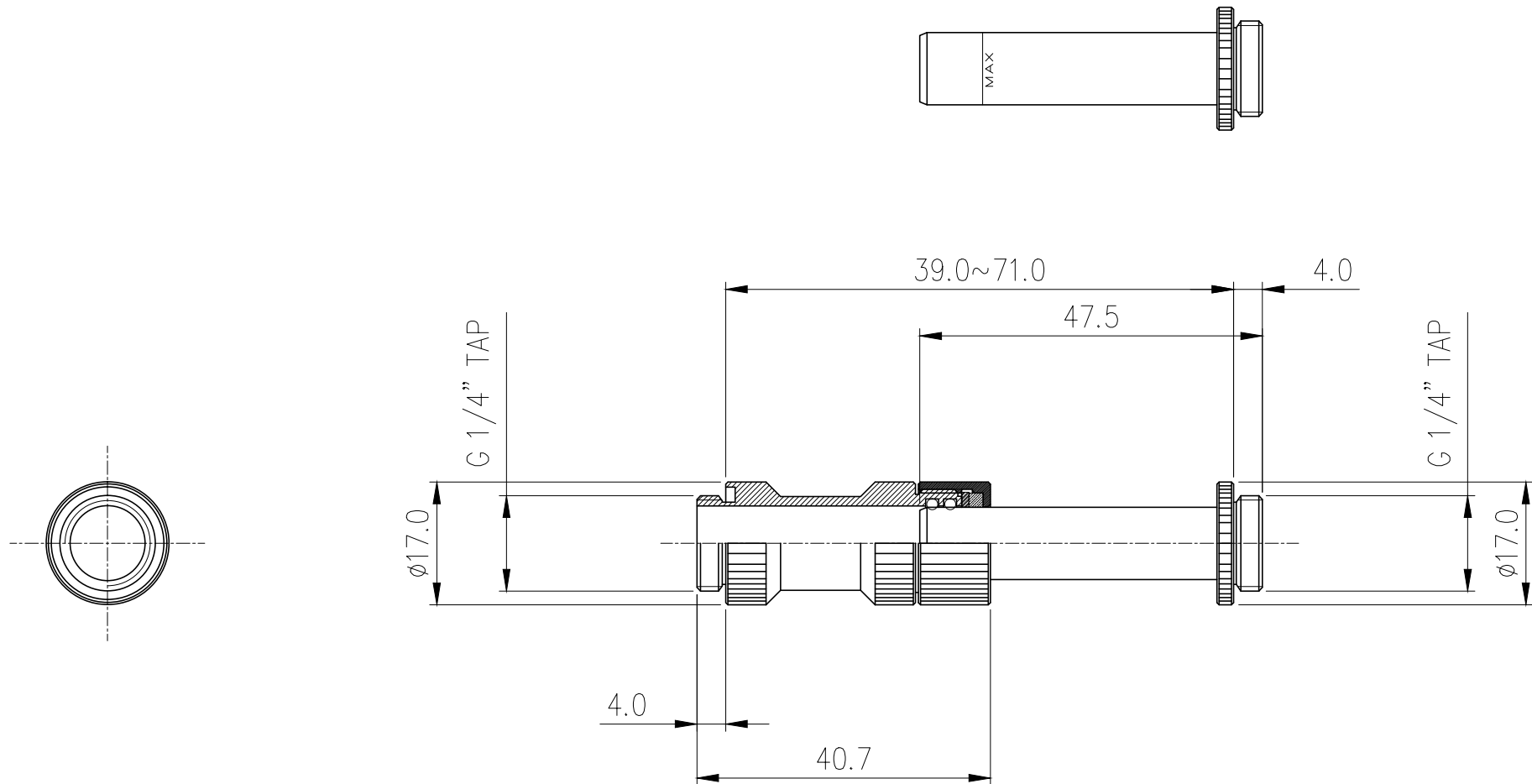

NO.		DESCRIPTION				MATER'L		QUANTITY	REMARKS
		UNIT		MM		SCALE		N/S	
		BY	BY	BY	BY	3RD ANGLE		TITLE	
DATE						CODE NO.		DWG. NO.	
04/10/2017		S.J.LEE							

APPAR		CNT-VDA34(-BK)		
		Ass'y		