




Koolance high quality, dual ball-bearing fan.


- Dimensions: 120x120x25mm
- Type: Dual Ball-Bearing
- Connector: 3-pin (3-wire with tachometer)
- Rated Voltage: 12VDC
- Current: 0.28A
- Speed: 2600RPM (max)
- Static Pressure: 5.4mm-H₂O
- Airflow: 107.6CFM (max)
- Noise: 32.80dBA (max)
- 50k hours MTBF

General	
Weight	0.40 lb (0.18 kg)
Noise (dBA)	32.8
Fans	
Airflow (CFM)	107.6
Current (A)	0.28
Size (mm)	120 x 120 x 25
Speed (RPM)	2600
Static Pressure (mm-H ₂ O)	5.4
Tachometer	yes
Type	Dual Ball Bearing
Voltage	12 VDC

P&Q Curve:

FAN-12025HBK

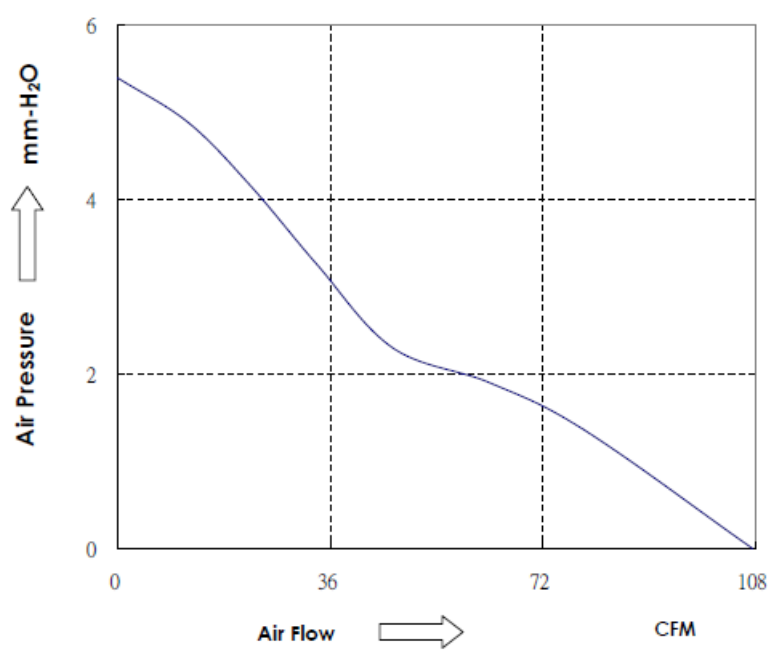

NO.		DESCRIPTION			PART NO.		QTY.	REMARKS
 KOOLANCE®					UNIT	MM	ITEM Fan	
					SCALE	N/S	TITLE	
					3RD ANGLE		120x25mm, High	
DATE	DRAWN BY	BY	BY	APPRO BY	KK CODE NO.		DRAWING NO.	REV.
AUG.10.2021	S.J.LEE			J.S.PARK	FAN-12025HBK		—	