




Koolance high quality, dual ball-bearing fan.


- Dimensions: 120x120x25mm
- Type: Dual Ball-Bearing
- Connector: 3-pin (3-wire with tachometer)
- Rated Voltage: 12VDC
- Current: 0.20A
- Speed: 2200RPM (max)
- Static Pressure: 4.1mm-H₂O
- Airflow: 89.5CFM (max)
- Noise: 30.10dBA (max)
- 50k hours MTBF

General	
Weight	0.40 lb (0.18 kg)
Noise (dBA)	30.1
Fans	
Airflow (CFM)	89.5
Current (A)	0.20
Size (mm)	120 x 120 x 25
Speed (RPM)	2200
Static Pressure (mm-H ₂ O)	4.1
Tachometer	yes
Type	Dual Ball Bearing
Voltage	12 VDC

P&Q Curve:

FAN-12025MBK

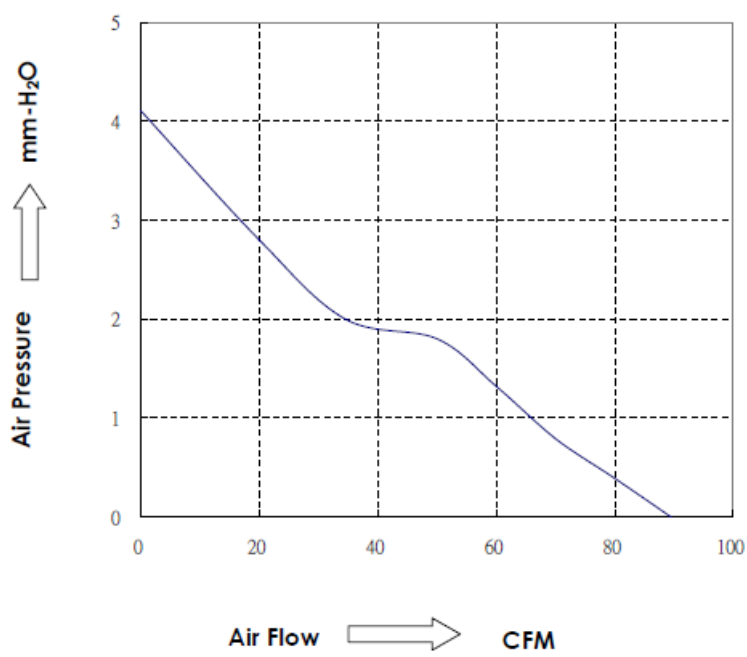

NO.		DESCRIPTION			PART NO.		QTY.	REMARKS
 KOOLANCE®					UNIT	MM	ITEM Fan	
					SCALE	N/S	TITLE	
					3RD ANGLE		120x25mm, Medium	
					DATE	DRAWN BY	BY	BY
AUG.09.2021	S.J.LEE			J.S.PARK	KK CODE NO. FAN-12025MBK		DRAWING NO. —	REV —