




Koolance high quality, dual ball-bearing fan. **[WARNING: This is a high amperage, high speed fan. Fan grills are highly recommended for safety!]**

- Dimensions: 120x120x38mm
- Type: Dual Ball-Bearing
- Connector: 3-pin (3-wire with tachometer)
- Rated Voltage: 12VDC
- Current: 2.0A
- Speed: 4000RPM (max)
- Static Pressure: 20.4mm-H2O
- Airflow: 183.5CFM (max)
- Noise: 59.00dBA (max)
- 50k hours MTBF

General	
Weight	0.70 lb (0.32 kg)
Noise (dBA)	59.0
Fans	
Airflow (CFM)	183.5
Current (A)	2.0
Size (mm)	120 x 120 x 38
Speed (RPM)	4000
Static Pressure (mm-H2O)	20.4
Tachometer	yes
Type	Dual Ball Bearing
Voltage	12 VDC

P&Q Curve:

FAN-12038HBK-184

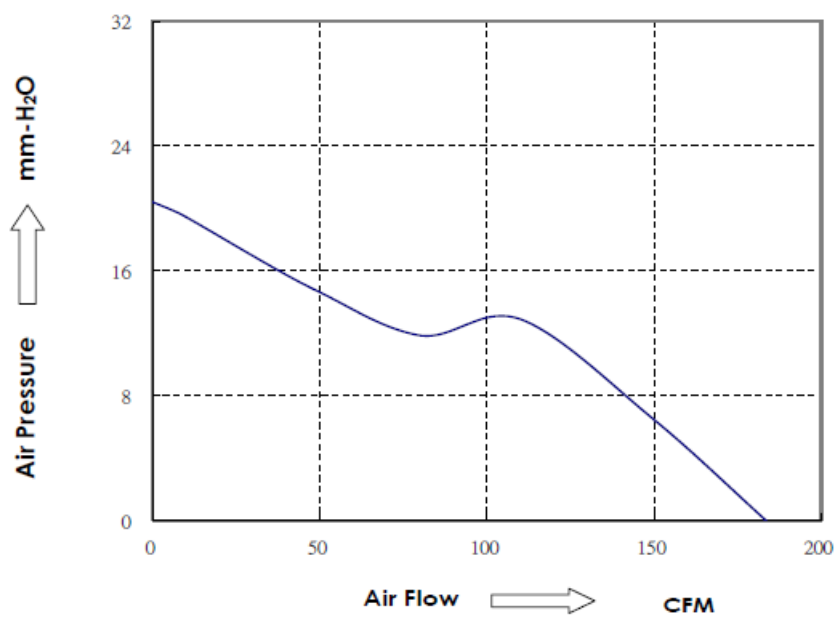

— YELLOW WIRE : UL1007 24AWG