



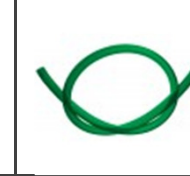
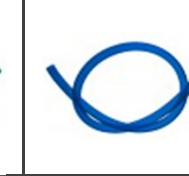
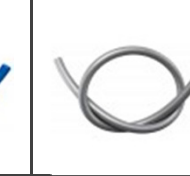
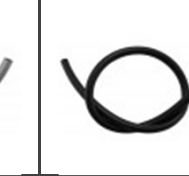





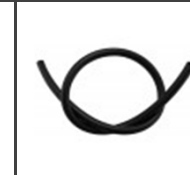



# Tubing

										
<b>Item Code</b>		<b>HOS-06X10PU-CL</b>	<b>HOS-06CL</b>	<b>HOS-10X13PU-CL</b>	<b>HOS-10X16CL</b>	<b>HOS-10GN</b>	<b>HOS-10BU</b>	<b>HOS-10SL</b>	<b>HOS-10BK</b>	<b>HOS-10CL</b>
<b>Weight</b>		0.04 lb (0.02 kg)	0.04 lb (0.02 kg)	0.06 lb (0.03 kg)	0.12 lb (0.05 kg)	0.06 lb (0.03 kg)	0.06 lb (0.03 kg)	0.06 lb (0.03 kg)	0.06 lb (0.03 kg)	0.06 lb (0.03 kg)
<b>Intended Tubing Size</b>	<b>ID</b>	6mm (1/4")	6mm (1/4")	10mm (3/8")	10mm (3/8")	10mm (3/8")	10mm (3/8")	10mm (3/8")	10mm (3/8")	10mm (3/8")
	<b>OD</b>	10mm (3/8")	10mm (3/8")	13mm (1/2")	16mm (5/8")	13mm (1/2")	13mm (1/2")	13mm (1/2")	13mm (1/2")	13mm (1/2")
	<b>Wall</b>	2mm (5/64")	2mm (5/64")	1.5mm (1/16")	3mm (1/8")	1.5mm (1/16")	1.5mm (1/16")	1.5mm (1/16")	1.5mm (1/16")	1.5mm (1/16")
<b>Materials</b>		polyurethane	PVC	polyurethane	PVC	PVC	PVC	PVC	PVC	PVC
<b>Max Pressure @25°C</b>		7kgf/cm2 (99.6psi)	6kgf/cm2 (64psi)	6kgf/cm2 (85psi)	5.5kgf/cm2 (78psi)	5kgf/cm2 (71psi)	5kgf/cm2 (71psi)	5kgf/cm2 (71psi)	5kgf/cm2 (71psi)	5kgf/cm2 (71psi)
<b>Max Temperature</b>		80°C (176°F)	70°C (158°F)	80°C (176°F)	70°C (158°F)	70°C (158°F)	70°C (158°F)	70°C (158°F)	70°C (158°F)	70°C (158°F)

							
<b>Item Code</b>		<b>HOS-13X19CL</b>	<b>HOS-13GN</b>	<b>HOS-13BU</b>	<b>HOS-13SL</b>	<b>HOS-13BK</b>	<b>HOS-13CL</b>
<b>Weight</b>		0.14 lb (0.06 kg)	0.09 lb (0.04 kg)	0.09 lb (0.04 kg)	0.09 lb (0.04 kg)	0.09 lb (0.04 kg)	0.09 lb (0.04 kg)
<b>Intended Tubing Size</b>	<b>ID</b>	13mm (1/2")	13mm (1/2")	13mm (1/2")	13mm (1/2")	13mm (1/2")	13mm (1/2")
	<b>OD</b>	19mm (3/4")	16mm (5/8")	16mm (5/8")	16mm (5/8")	16mm (5/8")	16mm (5/8")
	<b>Wall</b>	3mm (1/8")	1.5mm (1/16")	1.5mm (1/16")	1.5mm (1/16")	1.5mm (1/16")	1.5mm (1/16")
<b>Materials</b>		PVC	PVC	PVC	PVC	PVC	PVC
<b>Max Pressure @25°C</b>		4.5kgf/cm2 (64psi)	4kgf/cm2 (57psi)	4kgf/cm2 (57psi)	4kgf/cm2 (57psi)	4kgf/cm2 (57psi)	4kgf/cm2 (57psi)
<b>Max Temperature</b>		70°C (158°F)	70°C (158°F)	70°C (158°F)	70°C (158°F)	70°C (158°F)	70°C (158°F)