



Push-to-Connect Fitting for 1/2in (12.7mm) OD,  
G 1/4 BSPP



Koolance push-to-connect tube fitting for 1/2in (12.7mm) OD dense plastic tubing, G 1/4 BSPP thread. (Not for use with softer plastic materials, such as Koolance's PVC or PU tubing.) A toothed collet and dual o-rings secure tubing when inserted. To release tubing for removal, depress the outer ring.

General	
Weight	0.11 lb (0.05 kg)
Fitting Thread	G 1/4 BSPP
Max Pressure Tolerance @ 25° C	8kgf/cm2 (113.8psi)
Max Temperature Tolerance	80° C (176° F)
Min Storage Temperature (*No Freezing)	-30° C (-22° F)
Wetted Materials	Brass, Nickel Plating, EPDM

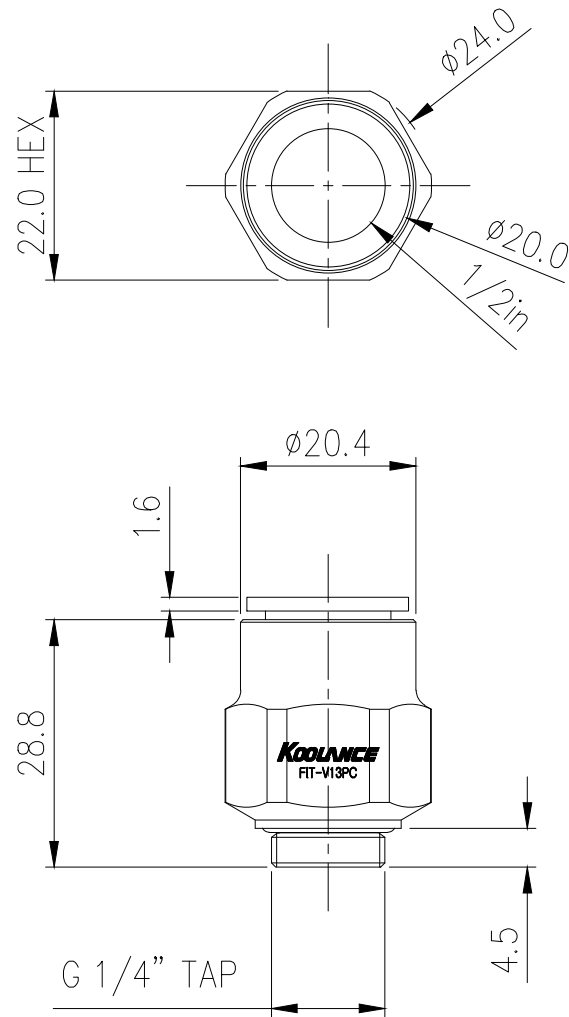

NO.		DESCRIPTION				MATER'L		QUANTITY	REMARKS			
						UNIT	MM	APPAR	FIT-V13PC			
		BY		BY	BY	APPRO	BY	Ass'y				
DATE										SCALE	N/S	TITLE
										3RD ANGLE		
AUG.03.2022		S.J.LEE						CODE NO.		DWG. NO.		