



Barb Fitting for ID 03mm (1/8in), G 1/4 BSPP

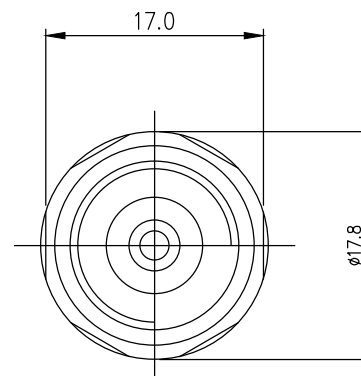


Single hose barb fitting for 1/8in (3mm) ID tubing. G 1/4 BSPP (parallel) thread. Includes hose clamp for 5mm (3/16in) OD tubing.

General	
Weight	0.03 lb (0.01 kg)
Max Pressure Tolerance @ 25° C	15kgf/cm2 (213.4psi)
Max Temperature Tolerance	120° C (248° F)
Wetted Materials	Nickel-Plated Brass, EPDM

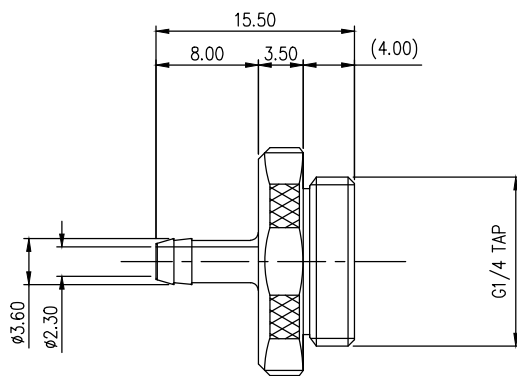

A			
REV	DATE	CONTENTS	APPD BY
REVISION			

NO.		DESCRIPTION			MATER'L		QUANTITY		REMARKS	
 KOOLANCE®					UNIT	MM	PART NO.		FIT-V03	
					SCALE	N/S	TITLE			
DATE		BY	BY	BY	APPRO BY	3RD ANGLE		G 1/4, 3mm (1/8") ID tubing		
2017.03.29		ys.shin								
						DWG. NO.		ITEM		