



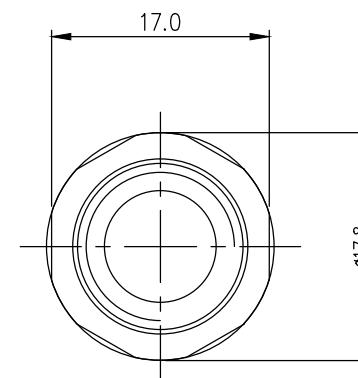

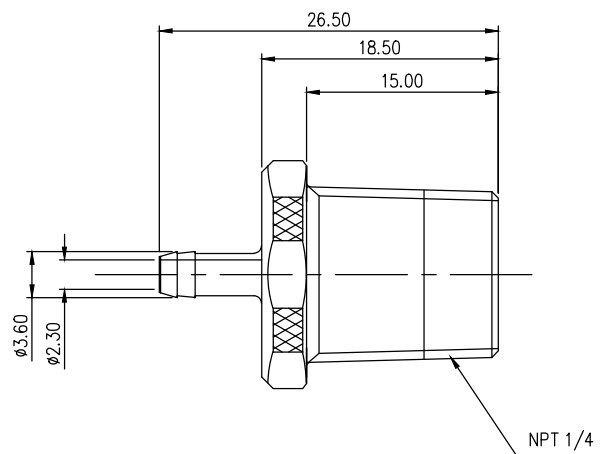

Single hose barb fitting for 1/8in (3mm) ID tubing. 1/4 NPT (tapered) thread. Includes hose clamp for 5mm (3/16in) OD tubing.

| General | |
|--------------------------------|---------------------------|
| Weight | 0.03 lb (0.01 kg) |
| Max Pressure Tolerance @ 25° C | 15kgf/cm2 (213.4psi) |
| Max Temperature Tolerance | 120° C (248° F) |
| Wetted Materials | Nickel-Plated Brass, EPDM |



| REV | DATE | CONTENTS | | APPD BY |
|----------|------|----------|--|---------|
| REVISION | | | | |

| | | | | | | | | | | |
|---|---------|---|----|-----------|-----------|-----|----------|--|----------------------------------|--|
| | | | | | | | | | | |
| NO. | | DESCRIPTION | | | MATER'L | | QUANTITY | | REMARKS | |
|  KOOLANCE | |  | | | UNIT | MM | PART NO. | | FIT-V03N14 | |
| | | | | | SCALE | N/S | TITLE | | NPT 1/4, 3mm (1/8") ID tubing | |
| DATE | BY | BY | BY | APPROD BY | 3RD ANGLE | | ITEM | | | |
| 2017.03.29 | ys.shin | | | | DWG. NO. | | | | | |
| | | | | | | | | | | |