



www.koolance.com

Specifications Sheet

Generated: 2024-04-26



P/N: FIT-V10N38


Barb Fitting for ID 10mm (3/8in), 3/8 NPT



Single hose barb fitting for 3/8in (10mm) ID tubing. 3/8 NPT (tapered) thread. Hose clamp for 1/2in (13mm) OD included.

General	
Weight	0.14 lb (0.06 kg)
Max Pressure Tolerance @ 25° C	15kgf/cm2 (213.4psi)
Max Temperature Tolerance	120° C (248° F)
Wetted Materials	Brass, Nickel Plating, EPDM

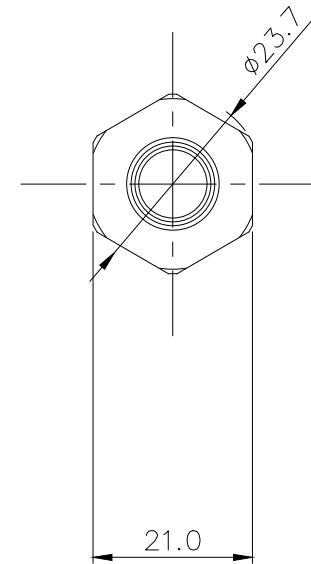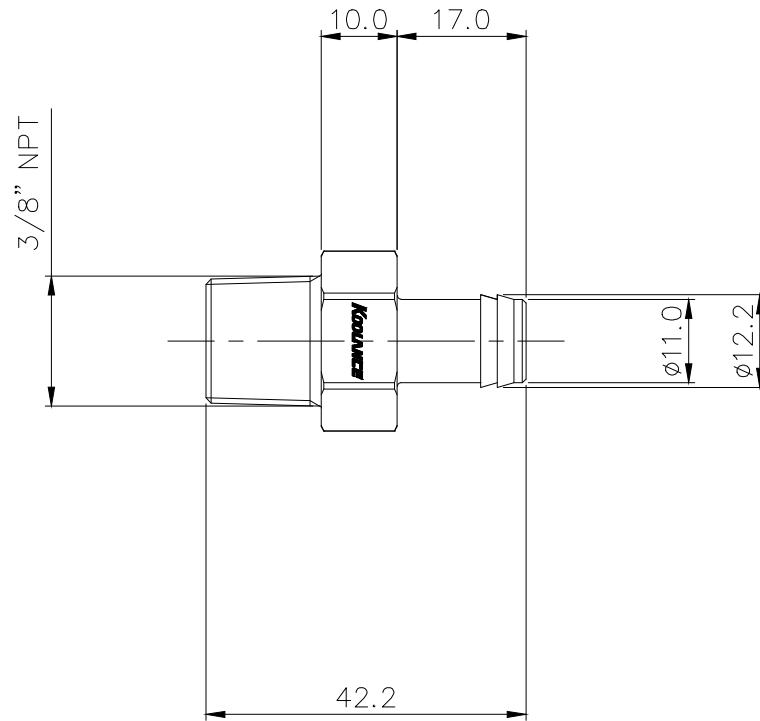

NO.		DESCRIPTION			MATER'L		QUANTITY	REMARKS
					UNIT	MM	ITEM FIT-V10N38	
					SCALE	N/S	TITLE	
					3RD ANGLE		Ass'y	
DATE	BY	BY	BY	APPRO BY				
	S.J.LEE				CODE NO.	DWG. NO.		PAGE