



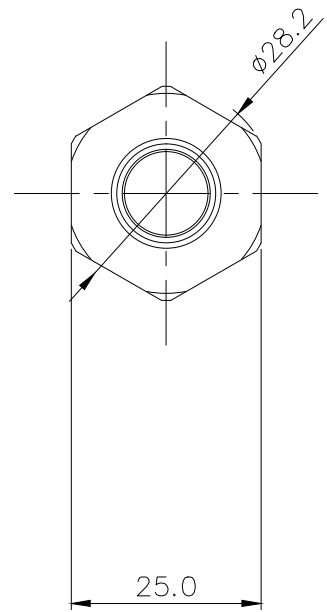


Single hose barb fitting for 1/2in (13mm) ID tubing. 1/2 NPT (tapered) thread. Hose clamp for 5/8in (16mm) OD included.

| General | |
|--------------------------------|-----------------------------|
| Weight | 0.19 lb (0.09 kg) |
| Max Pressure Tolerance @ 25° C | 15kgf/cm2 (213.4psi) |
| Max Temperature Tolerance | 120° C (248° F) |
| Wetted Materials | Brass, Nickel Plating, EPDM |

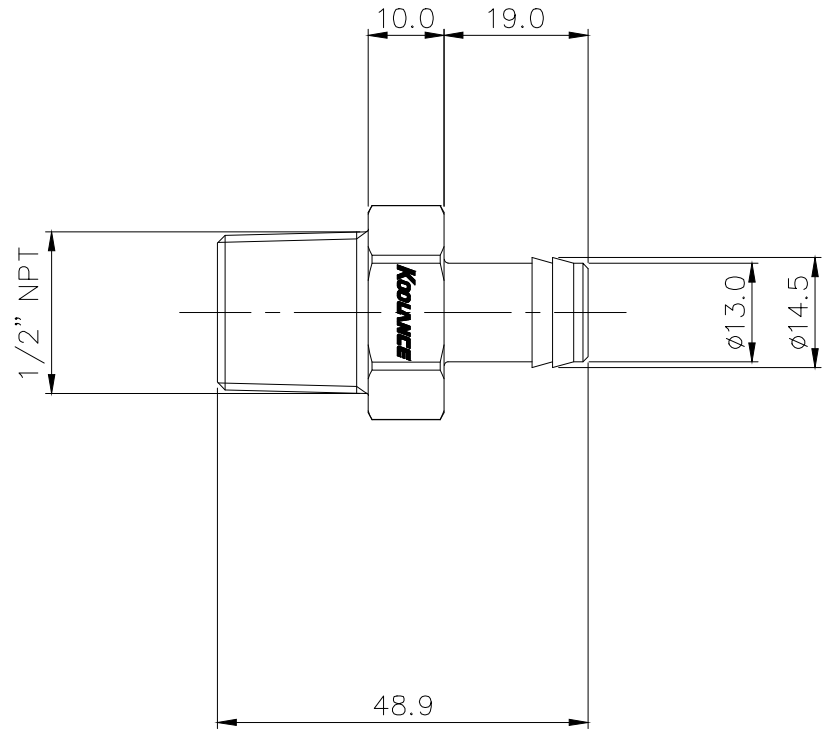

| | | | | | | | | | |
|--|--|-------------|----|----|----------|-----------|-----|--------------------|---------|
| | | | | | | | | | |
| NO. | | DESCRIPTION | | | | MATER'L | | QUANTITY | REMARKS |
|  KOOLANCE® | | | | | | UNIT | MM | ITEM FIT-V13N12 | |
| | | | | | | SCALE | N/S | TITLE Ass'y | |
| DATE | | BY | BY | BY | APPRD BY | 3RD ANGLE | | | |
| S.J.LEE | | | | | | CODE NO. | | DWG. NO. | PAGE |
| | | | | | | | | | |