



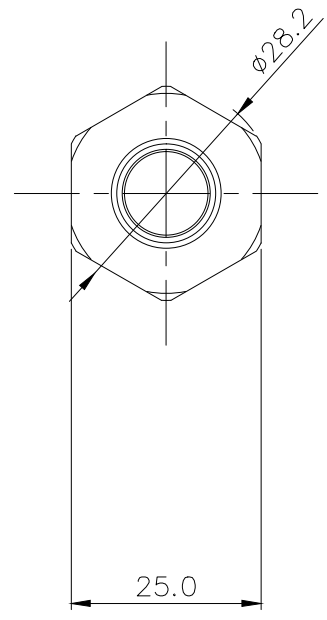

Single hose barb fitting for 1/2in (13mm) ID tubing. 1/2 NPT (tapered) thread. Hose clamp for 5/8in (16mm) OD included.

General	
Weight	0.19 lb (0.09 kg)
Materials	Brass, Nickel Plating, EPDM
Max Pressure Tolerance @ 25° C	15kgf/cm2 (213.4psi)
Max Temp. Operating Tolerance	120° C (248° F)

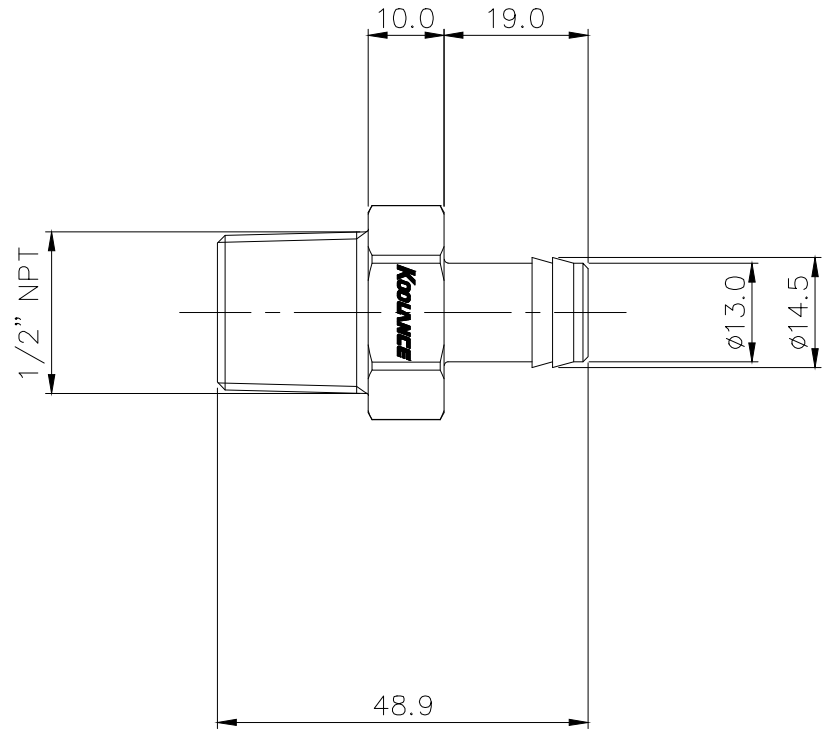

NO.	DESCRIPTION	MATER'L	QUANTITY	REMARKS
	<b>KOOLANCE</b>	UNIT	MM	ITEM FIT-V13N12
		SCALE	N/S	TITLE
	BY	BY	APPRO BY	Ass'y
DATE				
	S.J.LEE			3RD ANGLE
			CODE NO.	DWG. NO.
				PAGE