

Barb Fitting for ID 19mm (3/4in), G 3/8 BSPP




Single hose barb fitting for 3/4in (19mm) ID tubing. G 3/8 BSPP (parallel) thread. Hose clamp for 7/8in (22mm) OD included.

Intended Tubing Size



ID: 19mm (3/4")

OD: 22mm (7/8")

Wall: 1.5mm (1/16")

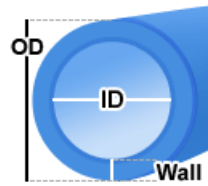

General	
Weight	0.16 lb (0.07 kg)
Materials	Brass, Nickel Plating, EPDM
Max Pressure @ 25 °C	15kgf/cm2 (213.4psi)
Max Temperature	120 °C (248 °F)

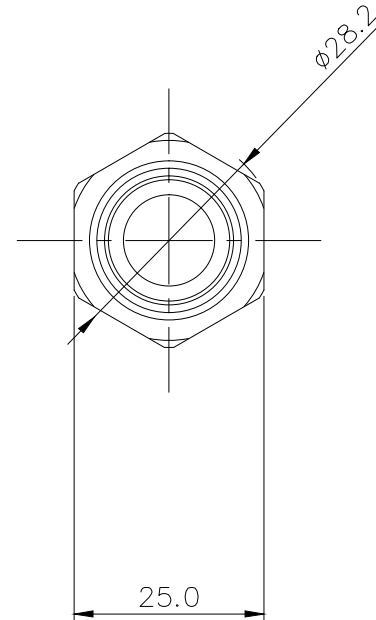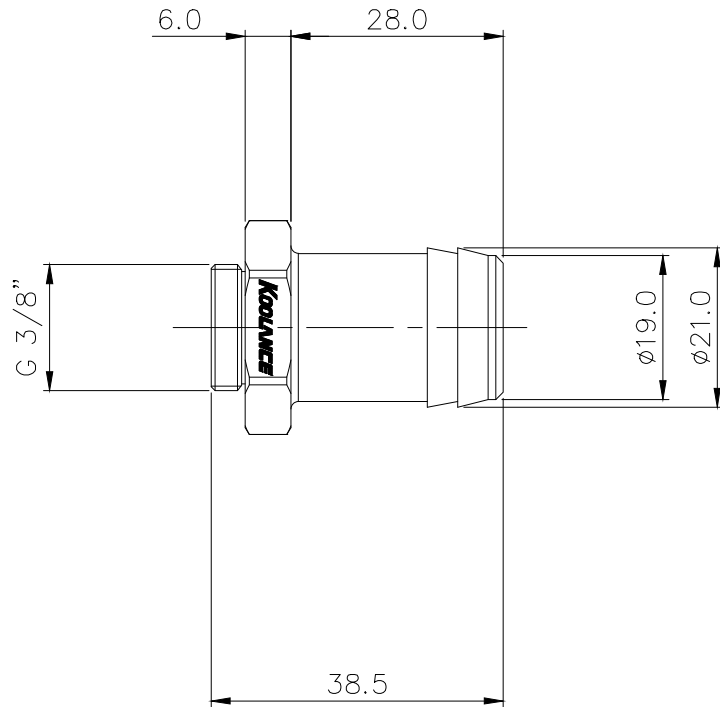

NO.	DESCRIPTION	MATER'L		QUANTITY	REMARKS
	Koolance	UNIT	MM	ITEM	FIT-V19G38
		SCALE	N/S	TITLE	
DATE	BY	BY	BY	APPRO	BY
	S.J.LEE			3RD ANGLE	
		CODE NO.		DWG. NO.	PAGE