



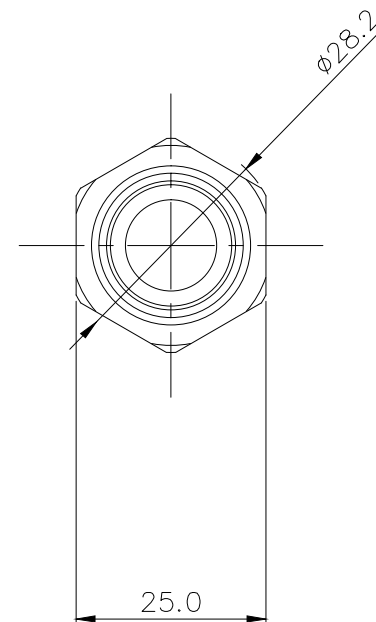


Single hose barb fitting for 3/4in (19mm) ID tubing. G 3/8 BSPP (parallel) thread. Hose clamp for 7/8in (22mm) OD included.

General	
Weight	0.16 lb (0.07 kg)
Max Pressure Tolerance @ 25° C	15kgf/cm2 (213.4psi)
Max Temperature Tolerance	120° C (248° F)
Wetted Materials	Brass, Nickel Plating, EPDM

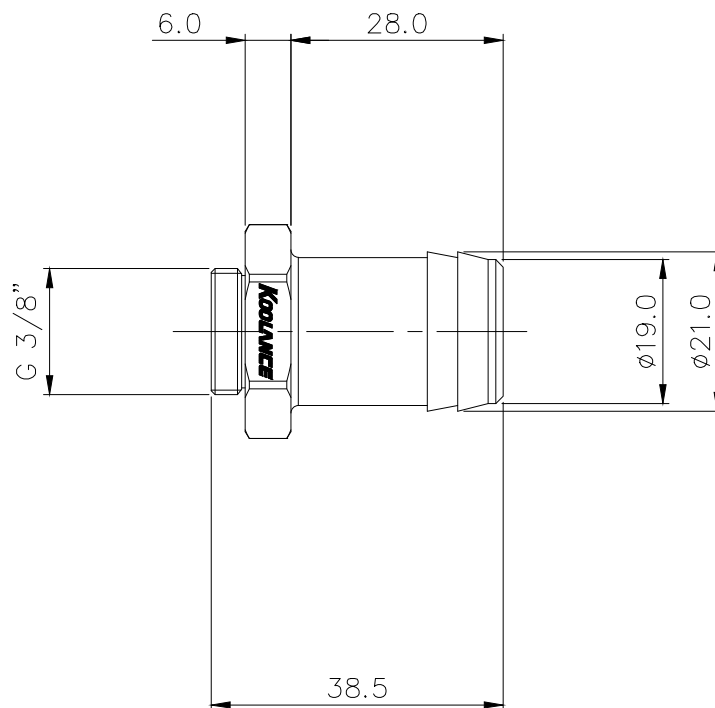

NO.	DESCRIPTION				MATER'L	QUANTITY	REMARKS
					UNIT	MM	ITEM FIT-V19G38
					SCALE	N/S	TITLE
	DATE	BY	BY	APPRO BY	3RD ANGLE		
	S.J.LEE				CODE NO.	DWG. NO.	PAGE

Ass'y