



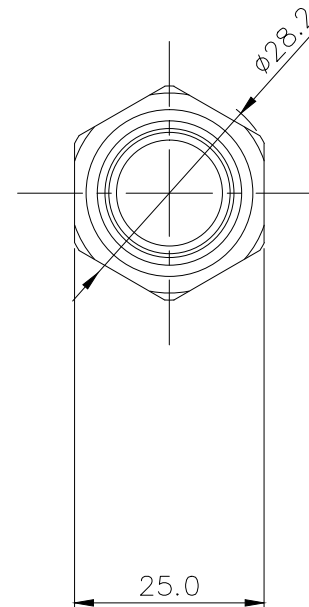


Single hose barb fitting for 3/4in (19mm) ID tubing. 1/2 NPT (tapered) thread. Hose clamp for 7/8in (22mm) OD included.

| General                        |                       |
|--------------------------------|-----------------------|
| Weight                         | 0.25 lb (0.11 kg)     |
| Max Pressure Tolerance @ 25° C | 15kgf/cm2 (213.4psi)  |
| Max Temperature Tolerance      | 120° C (248° F)       |
| Wetted Materials               | Brass, Nickel Plating |

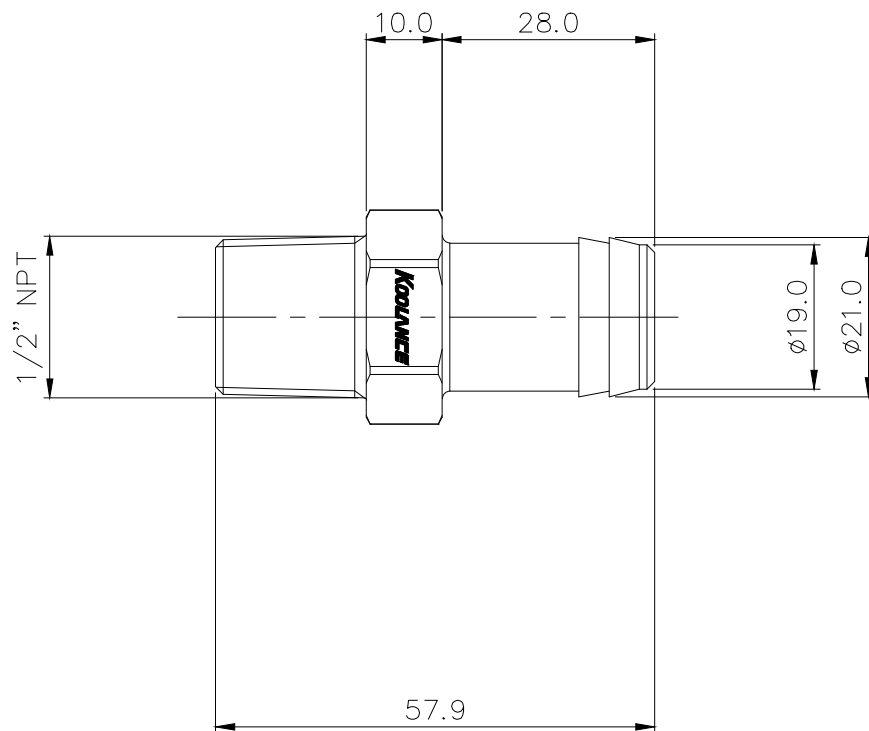

|   |         |             |    |       |    |          |     |          |            |
|---|---------|-------------|----|-------|----|----------|-----|----------|------------|
| NO.   |         | DESCRIPTION |    |       |    | MATER'L  |     | QUANTITY | REMARKS    |
|  |         |             |    |       |    | UNIT     | MM  | ITEM     | FIT-V19N12 |
|   |         |             |    |       |    | SCALE    | N/S | TITLE    |            |
| DATE  | BY      | BY          | BY | APPRO | BY | Ass'y    |     |          |            |
|   |         |             |    |       |    |          |     |          |            |
|   | S.J.LEE |             |    |       |    | CODE NO. |     | DWG. NO. |            |
|   |         |             |    |       |    |          |     |          | PAGE       |