



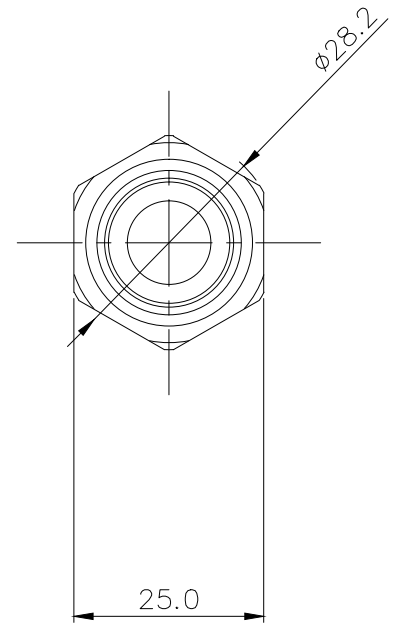

Single hose barb fitting for 3/4in (19mm) ID tubing. 3/8 NPT (tapered) thread. Hose clamp for 7/8in (22mm) OD included.

| General                        |                                  |
|--------------------------------|----------------------------------|
| Weight                         | 0.03 lb (0.01 kg)                |
| Max Pressure Tolerance @ 25 °C | 15kgf/cm <sup>2</sup> (213.4psi) |
| Max Temperature Tolerance      | 120 °C (248 °F)                  |
| Wetted Materials               | Brass, Nickel Plating            |

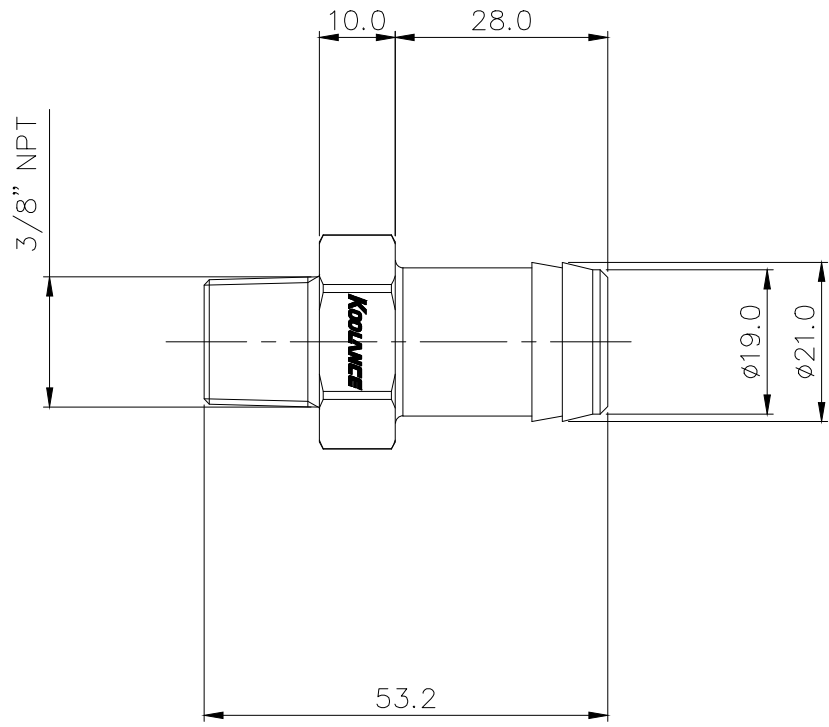

|      |                 |         |          |                 |
|------|-----------------|---------|----------|-----------------|
| NO.  | DESCRIPTION     | MATER'L | QUANTITY | REMARKS         |
|      | <b>Koolance</b> | UNIT    | MM       | ITEM FIT-V19N38 |
|      |                 | SCALE   | N/S      | TITLE           |
| DATE | BY              | BY      | APPRO BY | 3RD ANGLE       |
|      | S.J.LEE         |         |          | CODE NO.        |
|      |                 |         |          | DWG. NO.        |
|      |                 |         |          | PAGE            |

Ass'y