



www.koolance.com

Specifications Sheet

Generated: 2024-04-24


P/N: ADT-DXG45-BK


Fitting Single, \*Black\* Swiveling 45-Degree, G  
1/4 BSPP



Koolance swiveling G 1/4 BSPP socket fitting with a 45-degree bend.

General	
Weight	0.05 lb (0.02 kg)
Fitting Thread	G 1/4 BSPP
Max Pressure Tolerance @ 25°C	8kgf/cm2 (113.8psi)
Max Temperature Tolerance	100°C (212°F)
Wetted Materials	Brass, EPDM

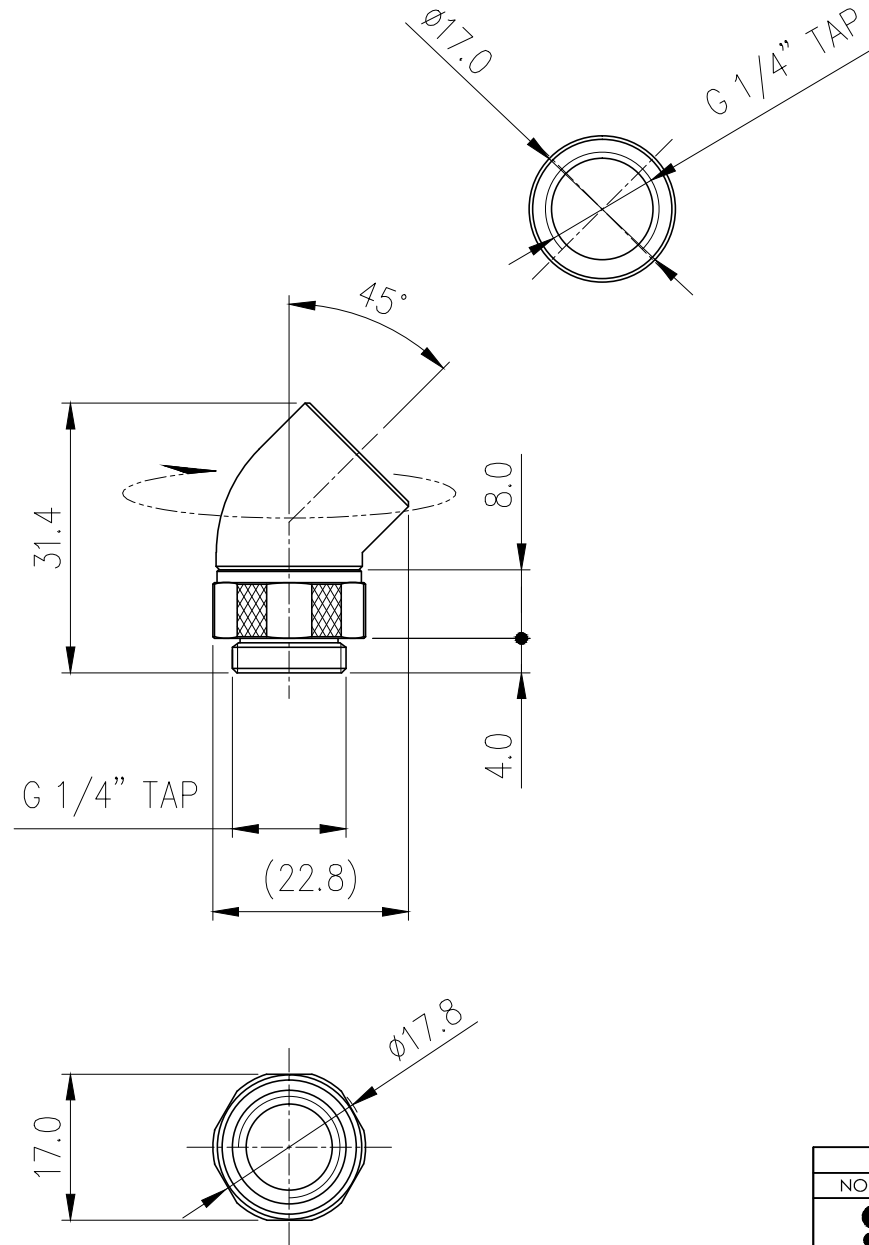

NO.		DESCRIPTION			MATER'L		QUANTITY	REMARKS
					UNIT	MM	APPAR	ADT-DXG45
					SCALE	N/S	TITLE  Ass'y	
DATE		BY	BY	BY	APPRO	BY		
					3RD ANGLE			DWG. NO.
04/06/2017		S.J.LEE			CODE NO.			