

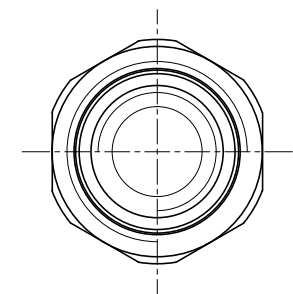


Compression Fitting for 10mm x 13mm (3/8in x 1/2in), G 1/4 BSPP

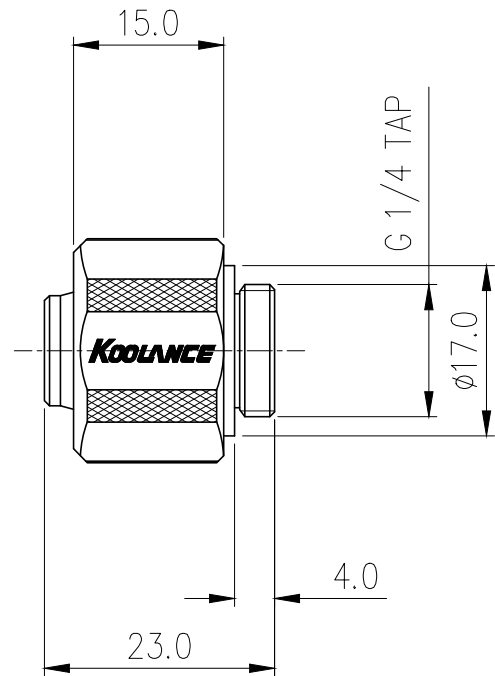

Single fitting for 3/8in (10mm) ID, 1/2in (13mm) OD tubing. G 1/4 BSPP (parallel) thread fitting.

| General                        |                             |
|--------------------------------|-----------------------------|
| Weight                         | 0.07 lb (0.03 kg)           |
| Max Pressure Tolerance @ 25° C | 15kgf/cm2 (213.4psi)        |
| Max Temperature Tolerance      | 120° C (248° F)             |
| Wetted Materials               | Brass, Nickel Plating, EPDM |

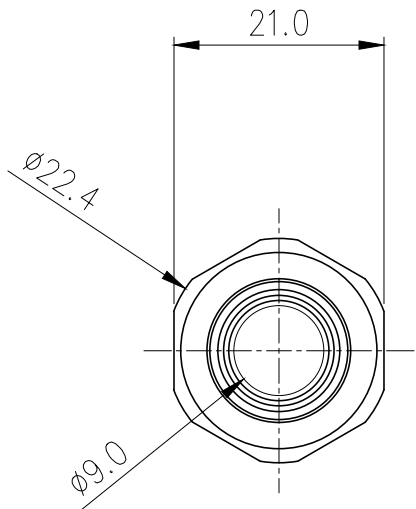

| REV      | DATE | CONTENTS | REVD BY | CHKD BY | APPD BY |
|----------|------|----------|---------|---------|---------|
|          |      |          |         |         |         |
| REVISION |      |          |         |         |         |

| NO.             | DESCRIPTION |    |    | MATER'L   | QUANTITY | REMARKS               |
|-----------------|-------------|----|----|-----------|----------|-----------------------|
| <b>KOOLANCE</b> |             |    |    | UNIT      | MM       | APPAR FIT-V10X13(-BK) |
| DATE            | BY          | BY | BY | SCALE     | N/S      | TITLE                 |
| 05.01.2014      | S.J.LEE     |    |    | 3RD ANGLE |          | Ass'y                 |
|                 |             |    |    | REF. NO.  |          | DWG. NO.              |