

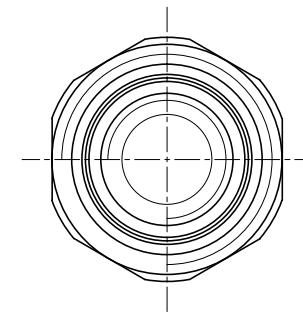


Compression Fitting for 10mm x 16mm (3/8in x 5/8in) *Black*, G 1/4 BSPP

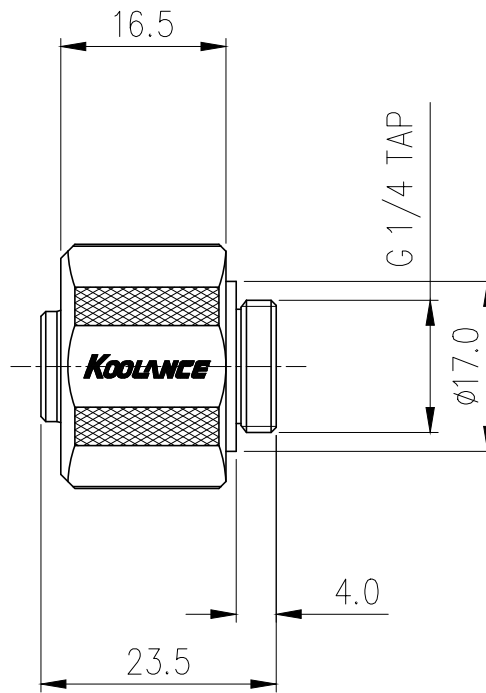

Single fitting for 3/8in (10mm) ID, 5/8in (16mm) OD tubing. G 1/4 BSPP (parallel) thread fitting.

| General | |
|--------------------------------|----------------------|
| Weight | 0.09 lb (0.04 kg) |
| Max Pressure Tolerance @ 25 °C | 15kgf/cm2 (213.4psi) |
| Max Temperature Tolerance | 120 °C (248 °F) |
| Wetted Materials | Brass, EPDM |

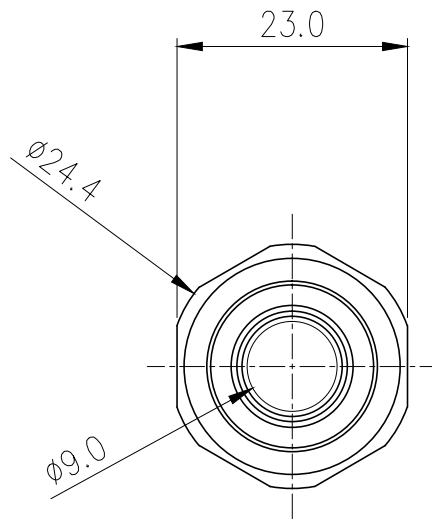

| REV | DATE | CONTENTS | REVD BY | CHKD BY | APPD BY |
|----------|------|----------|---------|---------|---------|
| | | | | | |
| | | | | | |
| REVISION | | | | | |

| NO. | DESCRIPTION | | | MATER'L | | QUANTITY | REMARKS |
|----------------------|-------------|----|----|-----------|-----|-----------------------|---------|
| Koolance Inc. | | | | UNIT | MM | APPAR FIT-V10X16(-BK) | |
| DATE | BY | BY | BY | SCALE | N/S | TITLE Ass'y | |
| 05.01.2014 | S.J.LEE | | | 3RD ANGLE | | | |
| | | | | REF. NO. | | DWG. NO. | |