

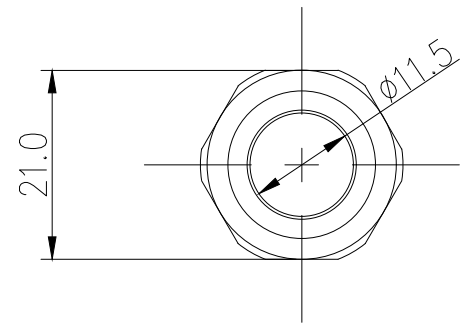


**Rotary Elbow Barb Fitting for 13mm (1/2in) ID,  
3/8 NPT**

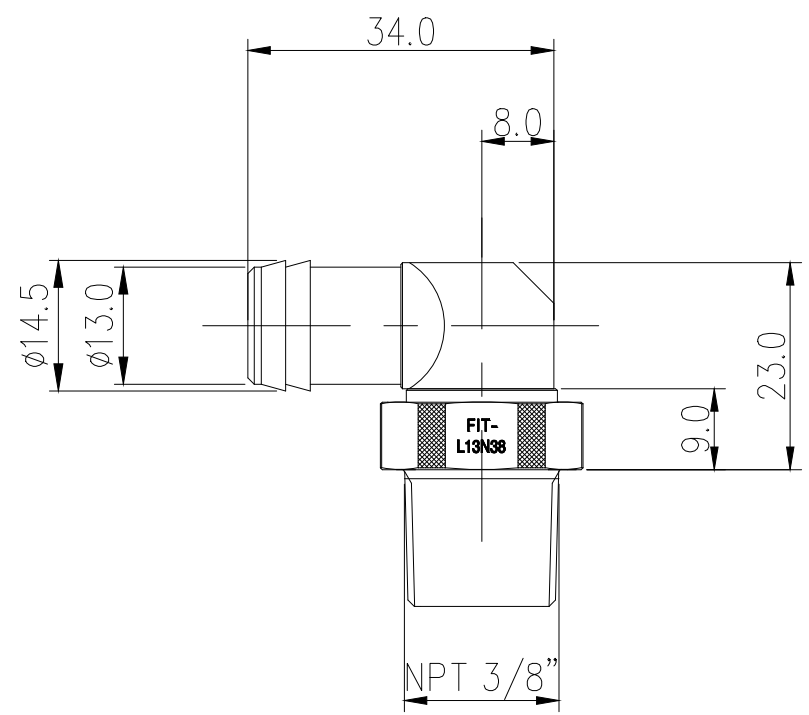

Single rotational angled fitting for 1/2in (13mm) ID tubing. 3/8 NPT (tapered) thread. Tube clamp for 5/8in (16mm) OD included.

| General                        |                                 |
|--------------------------------|---------------------------------|
| Weight                         | 0.13 lb (0.06 kg)               |
| Max Pressure Tolerance @ 25° C | 8kgf/cm <sup>2</sup> (113.8psi) |
| Max Temperature Tolerance      | 100° C (212° F)                 |
| Wetted Materials               | Brass, Nickel Plating, EPDM     |

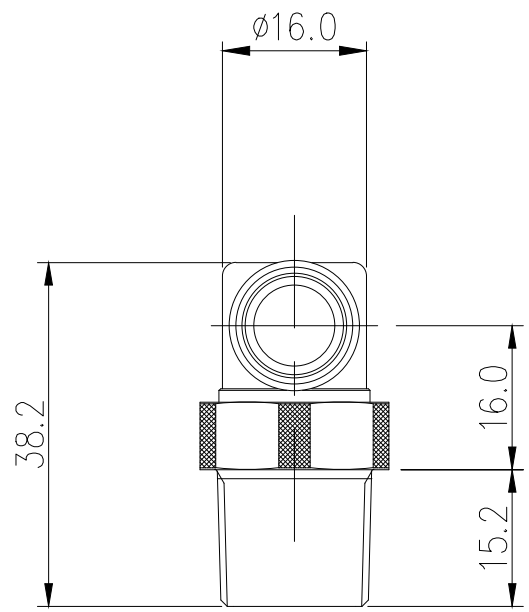

| NO.  | DESCRIPTION     |    |    |           | MATER'L   |          | QUANTITY | REMARKS    |
|------|-----------------|----|----|-----------|-----------|----------|----------|------------|
|      | <b>KOOLANCE</b> |    |    |           | UNIT      | MM       | APPAR    | FIT-L13N38 |
|      |                 |    |    |           | SCALE     | N/S      | TITLE    | Ass'y      |
| DATE | BY              | BY | BY | APPROD BY | 3RD ANGLE |          |          |            |
|      | SK.AN           |    |    |           | CODE NO.  | DWG. NO. |          |            |