

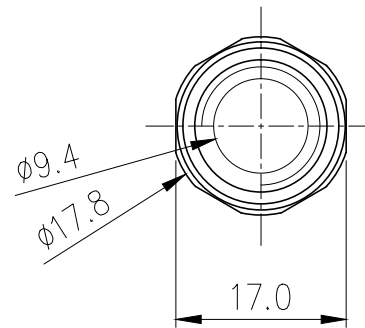


Rotary Elbow Compression Fitting for 13mm x 19mm (1/2in x 3/4in) *Black*, G 1/4 BSPP

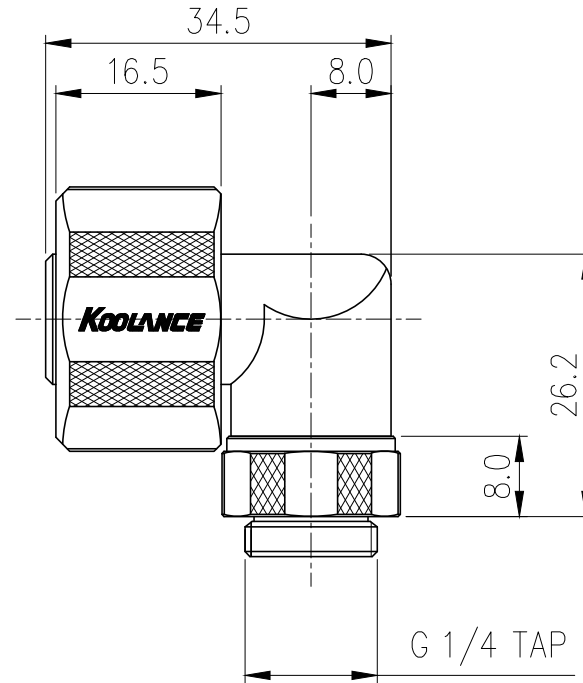

Single rotational angled fitting for 1/2in (13mm) ID, 3/4in (19mm) OD tubing. G 1/4 BSPP (parallel) thread.

General	
Weight	0.16 lb (0.07 kg)
Max Pressure Tolerance @ 25°C	8kgf/cm2 (113.8psi)
Max Temperature Tolerance	100°C (212°F)
Wetted Materials	Brass, EPDM

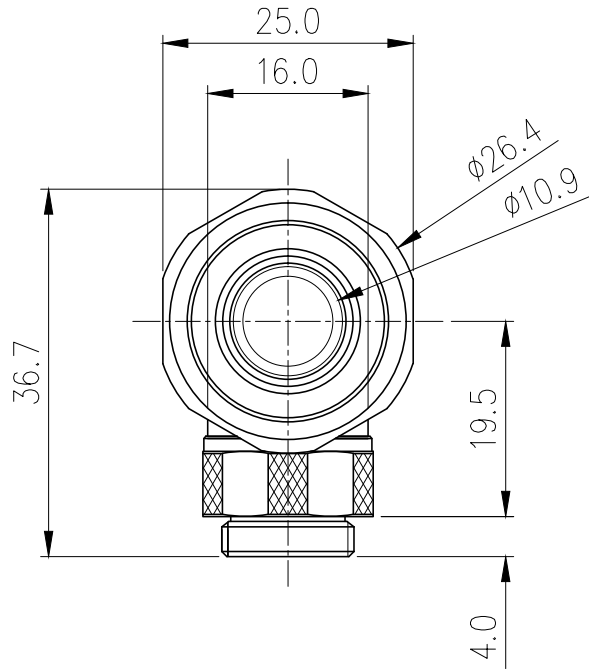

△					
△					
REV	DATE	CONTENTS	REVD BY	CHKD BY	APPD BY
REVISION					

NO.	DESCRIPTION			MATER'L	QUANTITY	REMARKS
KOOLANCE <small>INC.</small>		UNIT	MM	APPAR FIT-L13X19(-BK)		
		SCALE	N/S	TITLE		
DATE	BY	BY	BY	APPRD BY	3RD ANGLE	
04.30.2014	S.J.LEE				REF. NO.	DWG. NO.
				Ass'y		