

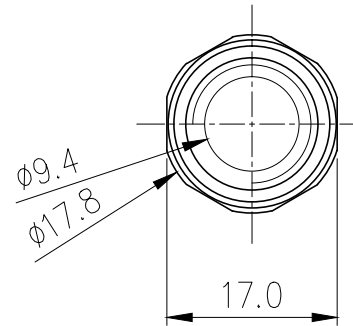


**Rotary Elbow Compression Fitting for 10mm x  
16mm (3/8in x 5/8in) \*Black\*, G 1/4 BSPP**

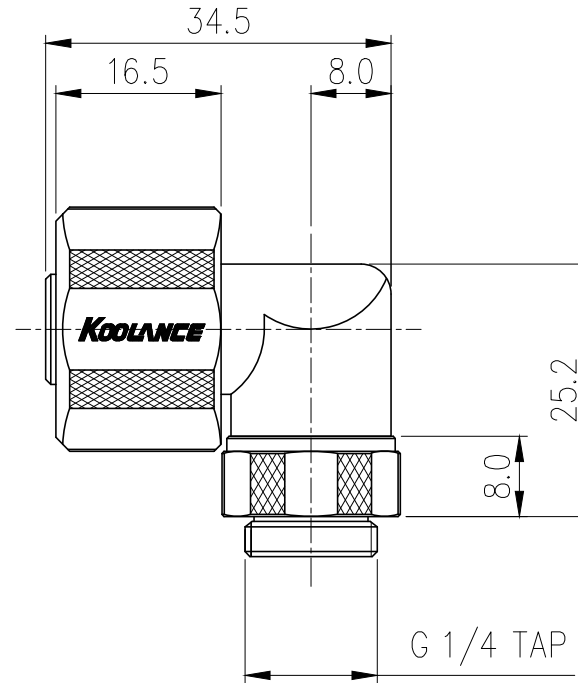

Single rotational angled fitting for 3/8in (10mm) ID, 5/8in (16mm) OD tubing. G 1/4 BSPP (parallel) thread.

General	
Weight	0.14 lb (0.06 kg)
Max Pressure Tolerance @ 25°C	8kgf/cm2 (113.8psi)
Max Temperature Tolerance	100°C (212°F)
Wetted Materials	Brass, EPDM

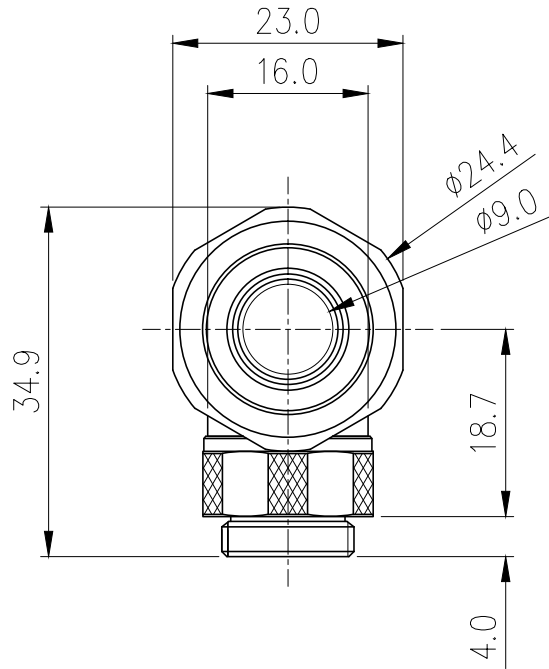

△					
△					
REV	DATE	CONTENTS	REVD BY	CHKD BY	APPD BY
REVISION					

NO.	DESCRIPTION			MATER'L		QUANTITY	REMARKS
	<b>KOOLANCE INC.</b>			UNIT	MM	APPAR	FIT-L10X16(-BK)
				SCALE	N/S		
	DATE	BY	BY	BY	APPRD BY	Ass'y	
	04.30.2014	S.J.LEE					
						REF. NO.	DWG. NO.