

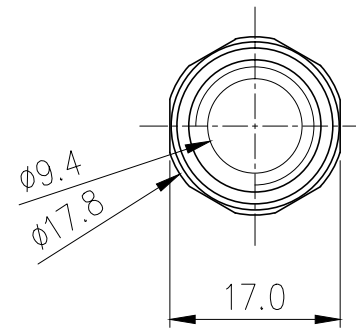


**Rotary Elbow Compression Fitting for 10mm x
16mm (3/8in x 5/8in) *Black*, G 1/4 BSPP**

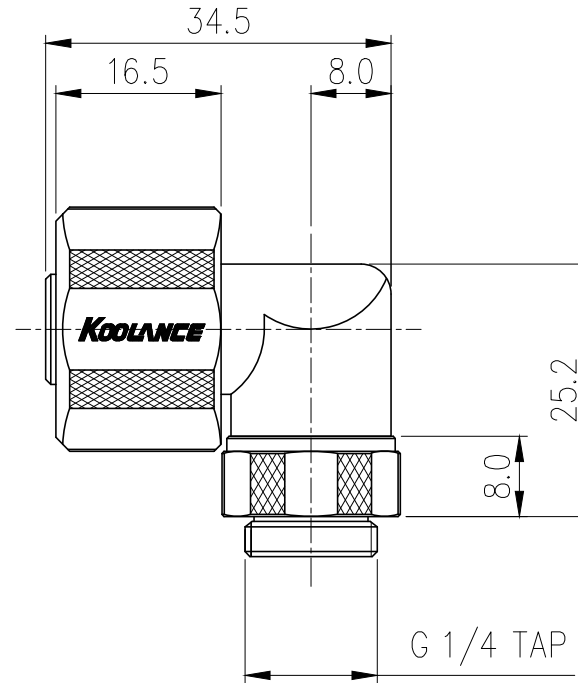

Single rotational angled fitting for 3/8in (10mm) ID, 5/8in (16mm) OD tubing. G 1/4 BSPP (parallel) thread.

General	
Weight	0.14 lb (0.06 kg)
Max Pressure Tolerance @ 25°C	8kgf/cm2 (113.8psi)
Max Temperature Tolerance	100°C (212°F)
Wetted Materials	Brass, EPDM

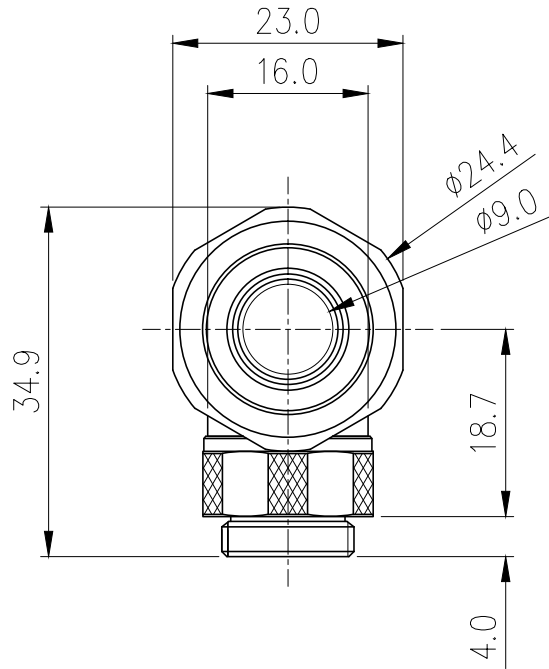

REV	DATE	CONTENTS	REVD BY	CHKD BY	APPD BY
REVISION					

NO.	DESCRIPTION			MATER'L		QUANTITY	REMARKS
KOOLANCE			UNIT	MM	APPAR FIT-L10X16(-BK)		
DATE	BY	BY	BY	APPRD BY	SCALE	N/S	Ass'y
04.30.2014	S.J.LEE				3RD ANGLE		
REF. NO.					DWG. NO.		