

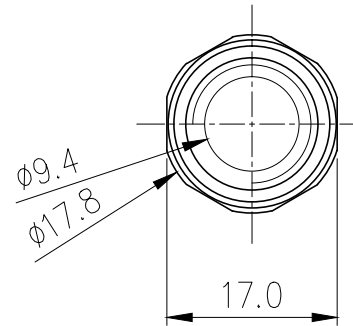


**Rotary Elbow Compression Fitting for 10mm x
16mm (3/8in x 5/8in), G 1/4 BSPP**

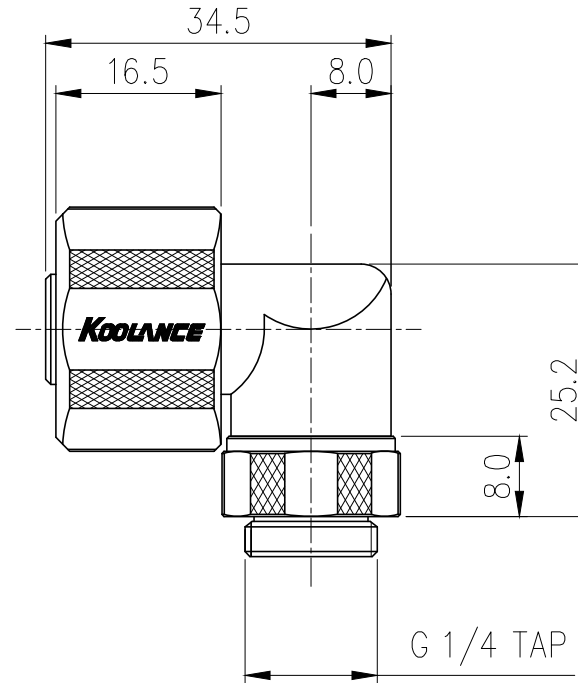

Single rotational angled fitting for 3/8in (10mm) ID, 5/8in (16mm) OD tubing. G 1/4 BSPP (parallel) thread.

| General | |
|--------------------------------|-----------------------------|
| Weight | 0.14 lb (0.06 kg) |
| Max Pressure Tolerance @ 25° C | 8kgf/cm2 (113.8psi) |
| Max Temperature Tolerance | 100° C (212° F) |
| Wetted Materials | Brass, Nickel Plating, EPDM |

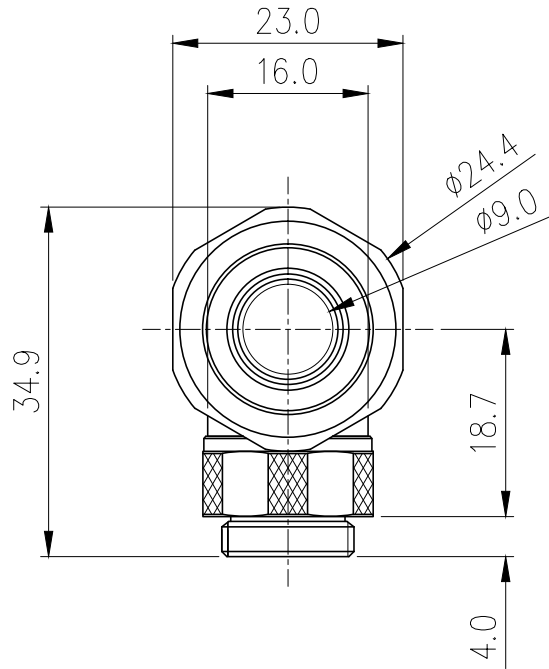

| REV | DATE | CONTENTS | REVD BY | CHKD BY | APPD BY |
|----------|------|----------|---------|---------|---------|
| | | | | | |
| REVISION | | | | | |

| NO. | DESCRIPTION | | | MATER'L | | QUANTITY | REMARKS |
|-----------------|-------------|----|------|----------|-----------------------|----------|---------|
| KOOLANCE | | | UNIT | MM | APPAR FIT-L10X16(-BK) | | |
| DATE | BY | BY | BY | APPRD BY | SCALE | N/S | Ass'y |
| 04.30.2014 | S.J.LEE | | | | 3RD ANGLE | | |
| REF. NO. | | | | | DWG. NO. | | |