


GPU-180-H06 Water Block (Video/Motherboard Chipset) [06mm, 1/4in ID]

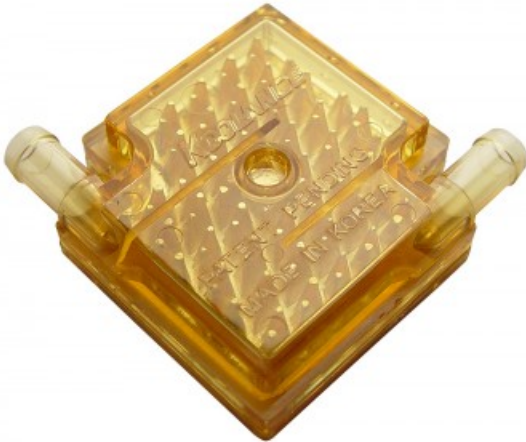

Featuring a very efficient 200W patented design, the GPU-180-H06 is Koolance's lowest-profile chipset cooler. It is created from high density solid copper and plated in gold.


Created from high density solid copper and plated in gold, the GPU-180 includes a sliding mounting bracket to fit all types of chipset mounting holes (video or motherboard). Two sizes of bracket tabs are included, plus mounting hooks for Intel chipsets and 8 aluminum self-adhesive video memory heat sinks.

Intended Tubing Size

ID: 6mm (1/4")


OD: 10mm (3/8")




Wall: 2mm (5/64")

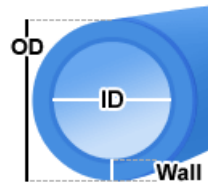


General	
Weight	0.40 lb (0.18 kg)
Materials	Gold-Plated Copper, Engineering Resin, Silicone

Thermal Resistance vs. Flow Rate

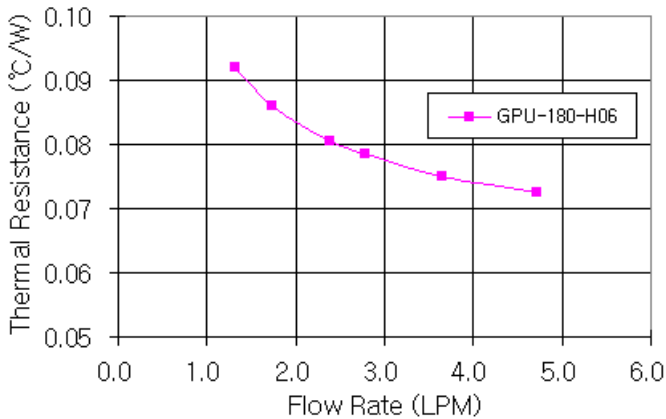

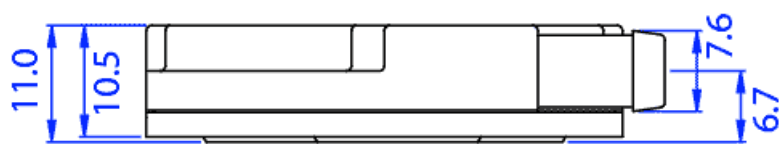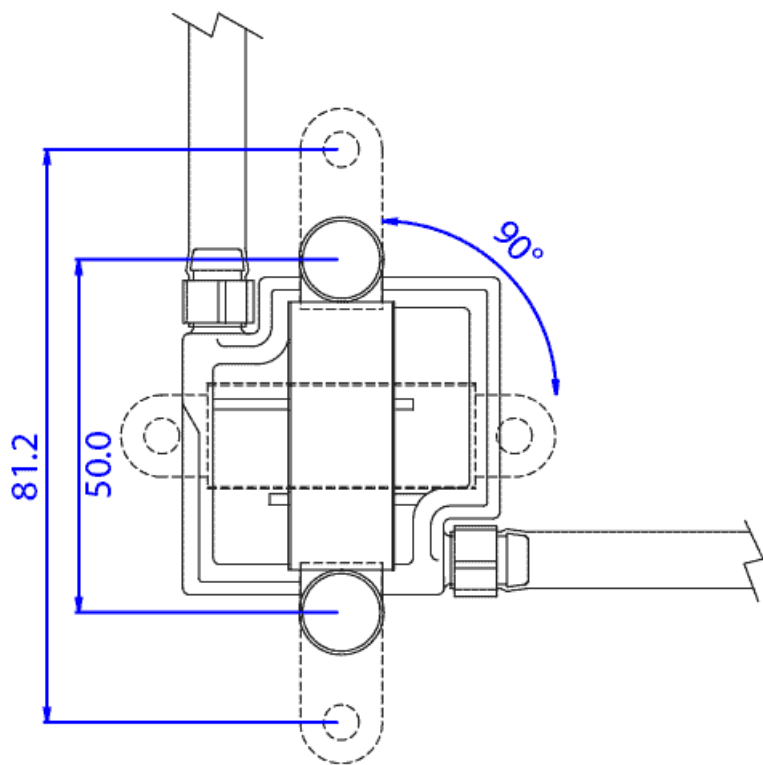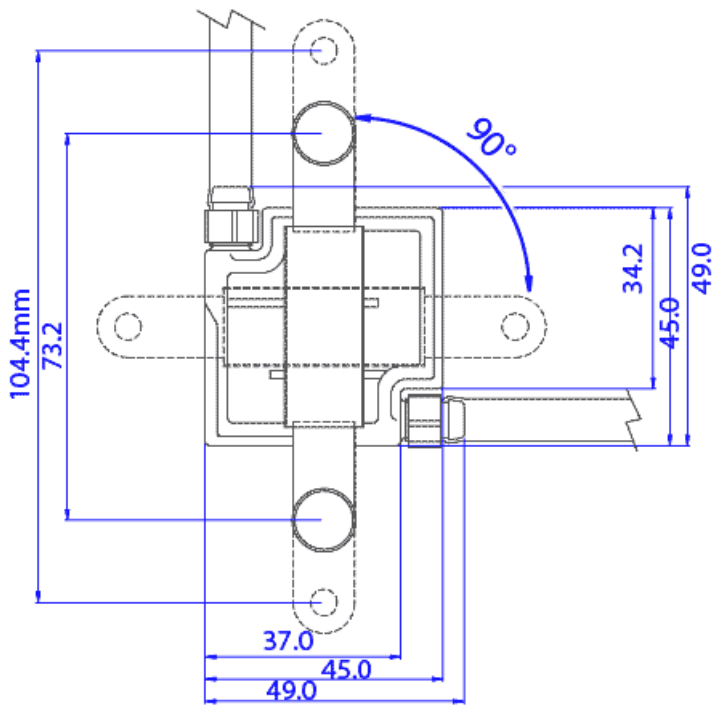

Pressure Drop vs. Flow Rate

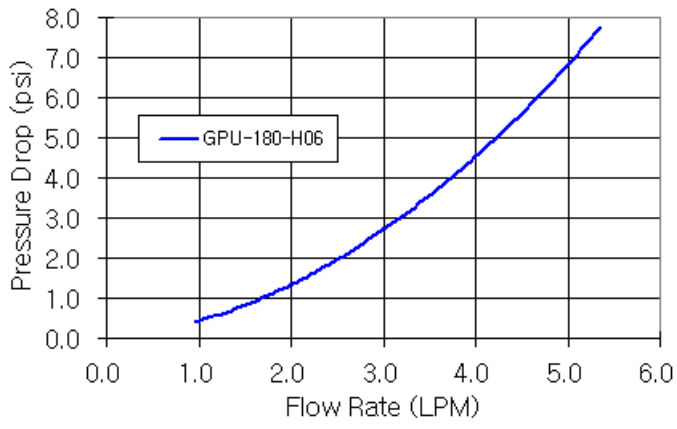

Thermal Resistance vs. Pressure Drop

