

P/N: HOS-10X17EP-10M


Hose, EPDM Black, Dia: 10mm x 17mm (3/8in x 11/16in) - [Length 10m / 32.8ft]



Koolance black EPDM thread-reinforced hose with 10mm (3/8in) internal diameter, 17mm (11/16in) external diameter. Length 10m / 32.8ft. Bend radius is approximately 35mm (1.38in).


General	
Weight	5.40 lb (2.45 kg)
Max Pressure Tolerance @ 25 °C	7.1kgf/cm ² (101.5psi)
Max Temperature Tolerance	120 °C (248 °F)
Hardness (Shore)	70A

Ø 11/16 in (17.5mm)

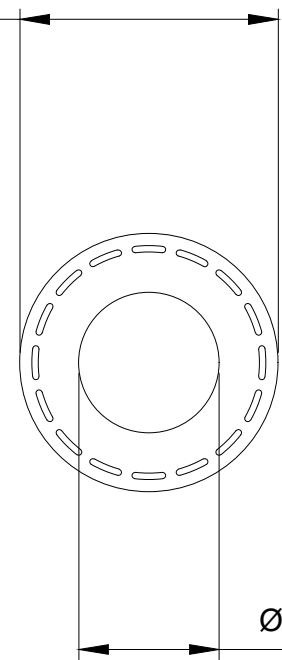


Ø 3/8 in (9.5mm)

LENGTH IS REPRESENTATIVE

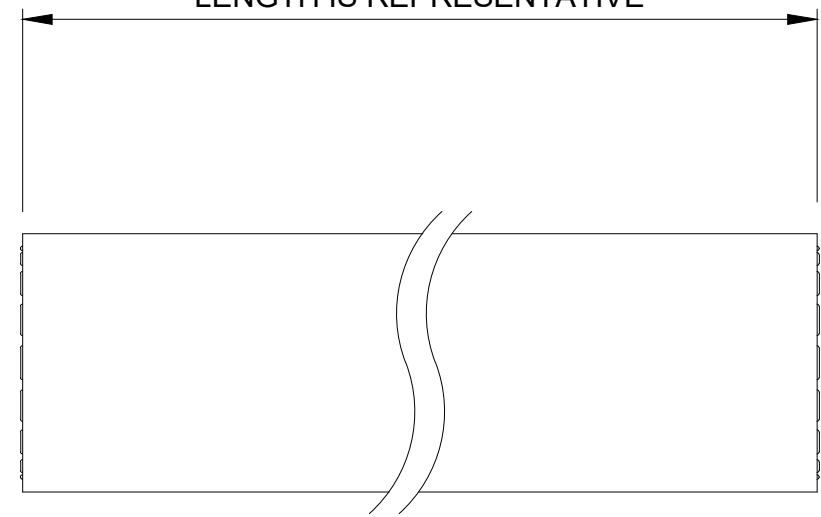

EPDM thread-reinforced

NO.	DESCRIPTION				MATER'L	QUANTITY	REMARKS
					UNIT	inch	APPAR
					SCALE	N/S	TITLE
DATE	BY	BY	BY	APPROD BY	3RD ANGLE		HOS-10X17EP-XX
2026.05.11	SK.An				CODE NO.	DWG. NO.	