




Koolance black EPDM thread-reinforced hose with 10mm (3/8in) internal diameter, 17mm (11/16in) external diameter. Length 3m / 9.8ft. Bend radius is approximately 35mm (1.38in).


General	
Weight	1.60 lb (0.73 kg)
Max Pressure Tolerance @ 25 °C	7.1kgf/cm ² (101.5psi)
Max Temperature Tolerance	120 °C (248 °F)
Hardness (Shore)	70A

Ø 11/16 in (17.5mm)

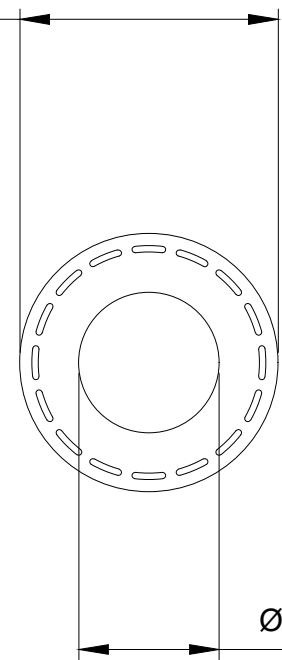


Ø 3/8 in (9.5mm)

LENGTH IS REPRESENTATIVE

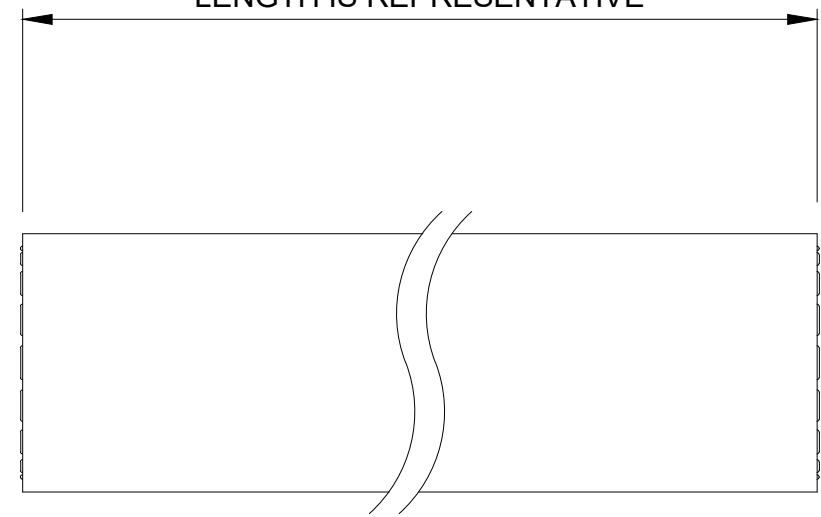

EPDM thread-reinforced

NO.	DESCRIPTION				MATER'L	QUANTITY	REMARKS
					UNIT	inch	APPAR
					SCALE	N/S	TITLE
DATE	BY	BY	BY	APPRO BY	3RD ANGLE		HOS-10X17EP-XX
2026.05.11	SK.An				CODE NO.	DWG. NO.	