



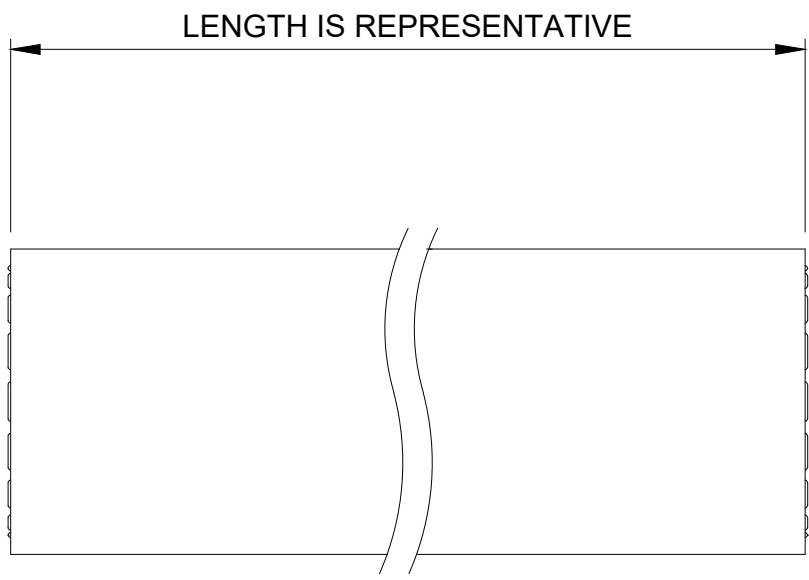


Koolance black EPDM thread-reinforced hose with 13mm (1/2in) internal diameter, 21mm (13/16in) external diameter. Length 50m / 164ft. Bend radius is approximately 50mm (1.97in).

General	
Weight	31.80 lb (14.42 kg)
Max Pressure Tolerance @ 25°C	7.1kgf/cm ² (101.5psi)
Max Temperature Tolerance	120°C (248°F)
Hardness (Shore)	70A

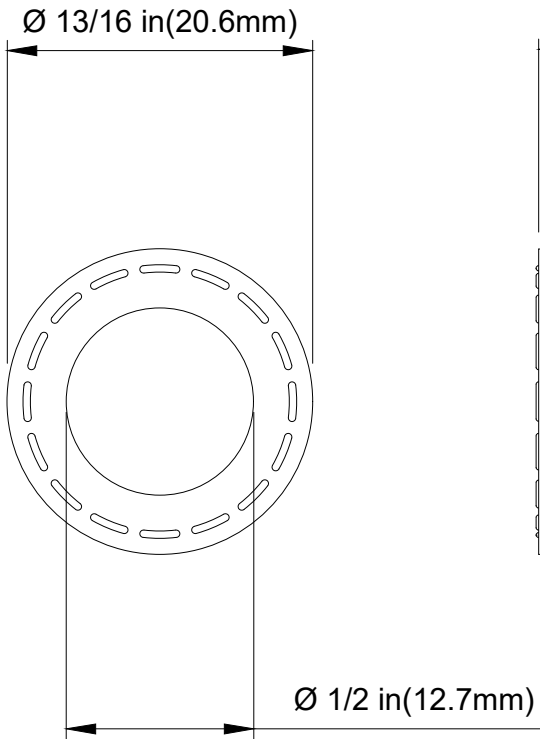

EPDM thread-reinforced

NO.	DESCRIPTION				MATER'L	QUANTITY	REMARKS
					UNIT	inch	APPAR
					SCALE	N/S	TITLE
DATE	BY	BY	BY	APPRD BY	3RD ANGLE		
2026.05.11	SK.An				CODE NO.	DWG. NO.	