



# P/N: HOS-16X24EP-10M

Hose, EPDM Black, Dia: 16mm x 24mm (5/8in x 15/16in) - [Length 10m / 32.8ft]




Koolance black EPDM thread-reinforced hose with 16mm (5/8in) internal diameter, 24mm (15/16in) external diameter. Length 10m / 32.8ft. Bend radius is approximately 55mm (2.17in).

General	
Weight	8.00 lb (3.63 kg)
Max Pressure Tolerance @ 25 °C	7.1kgf/cm2 (101.5psi)
Max Temperature Tolerance	120 °C (248 °F)
Hardness (Shore)	70A

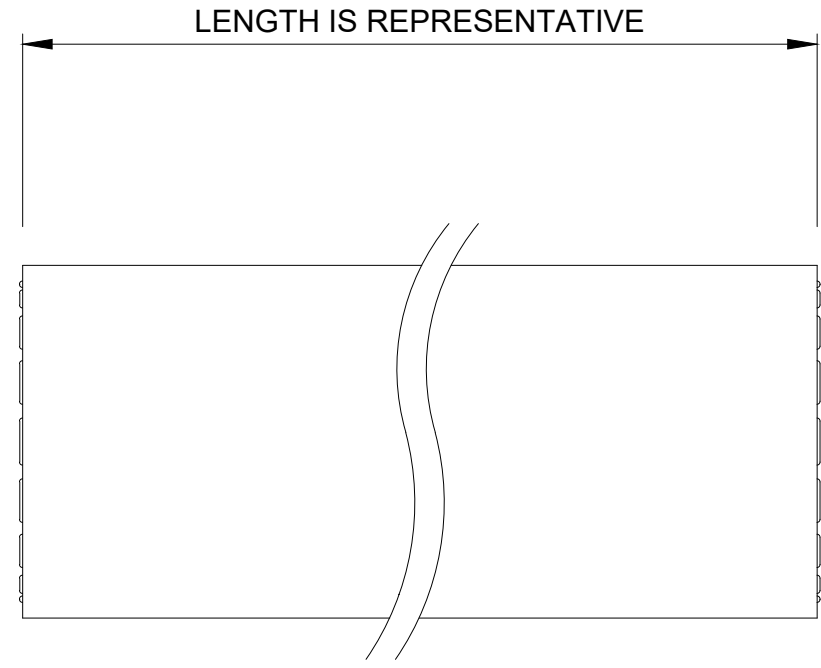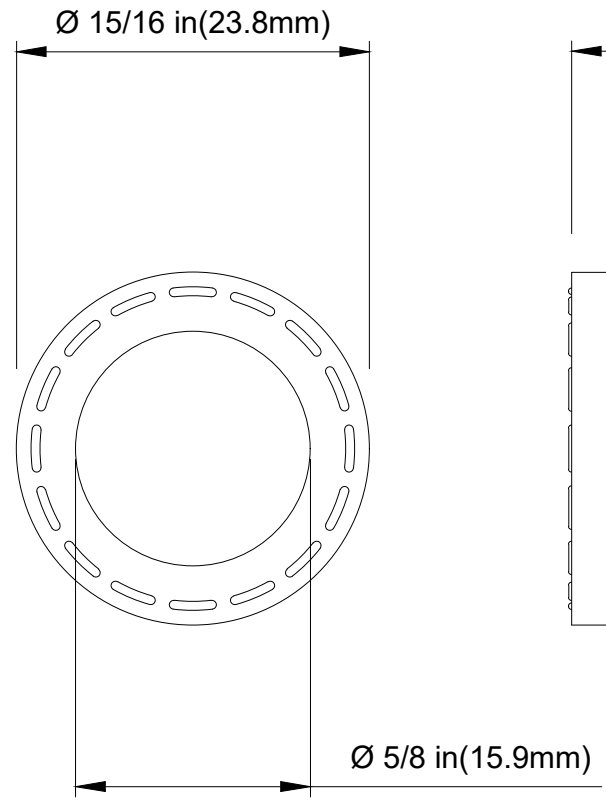

### EPDM thread-reinforced

NO.	DESCRIPTION				MATER'L	QUANTITY	REMARKS
					UNIT	inch	APPAR
					SCALE	N/S	TITLE
DATE	BY	BY	BY	APPRD BY	3RD ANGLE		
2026.05.11	SK.An				CODE NO.	DWG. NO.	