



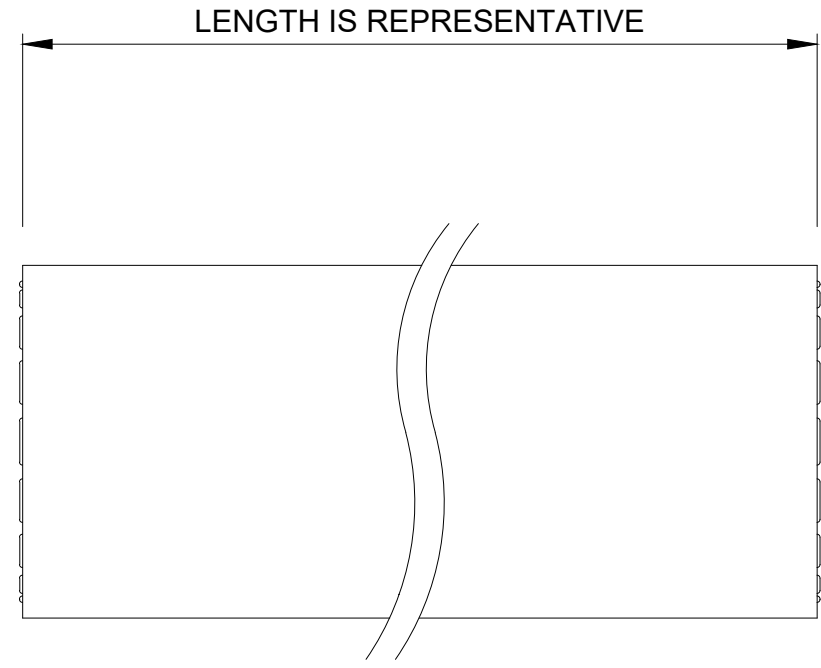


Koolance black EPDM thread-reinforced hose with 16mm (5/8in) internal diameter, 24mm (15/16in) external diameter. Length 3m / 9.8ft. Bend radius is approximately 55mm (2.17in).

General	
Weight	2.60 lb (1.18 kg)
Max Pressure Tolerance @ 25 °C	7.1kgf/cm2 (101.5psi)
Max Temperature Tolerance	120 °C (248 °F)
Hardness (Shore)	70A

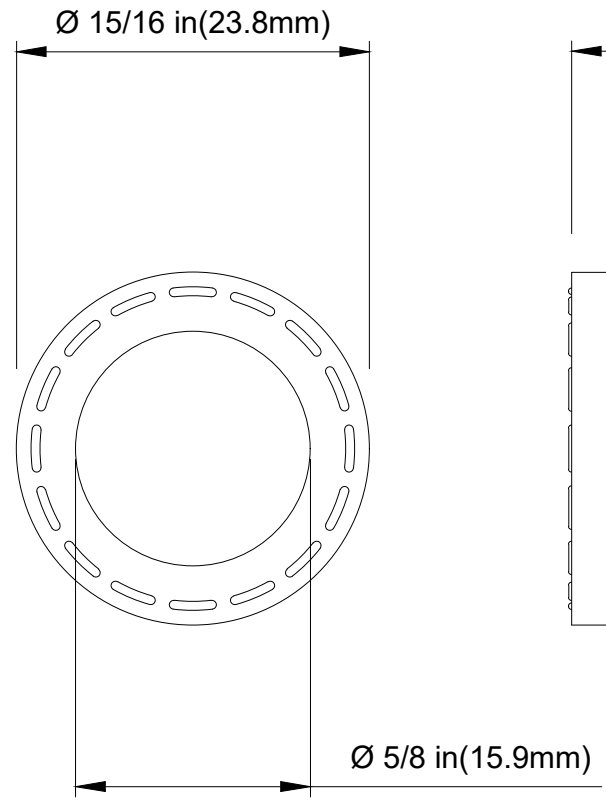

EPDM thread-reinforced

NO.	DESCRIPTION				MATER'L	QUANTITY	REMARKS
					UNIT	inch	APPAR
					SCALE	N/S	TITLE
DATE	BY	BY	BY	APPRD BY	3RD ANGLE		HOS-16X24EP-XX
2026.05.11	SK.An				CODE NO.	DWG. NO.	