



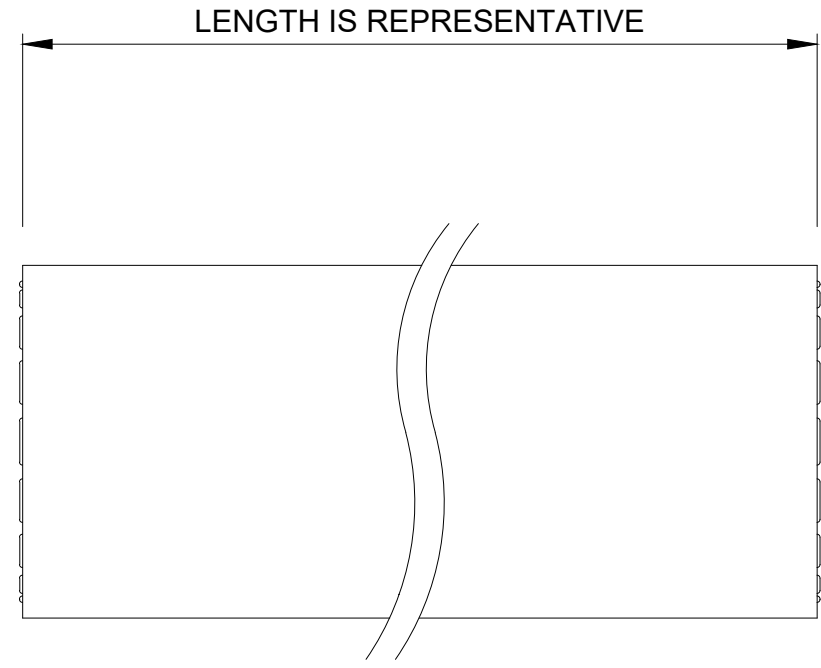


Koolance black EPDM thread-reinforced hose with 16mm (5/8in) internal diameter, 24mm (15/16in) external diameter. Length 50m / 164ft. Bend radius is approximately 55mm (2.17in).

General	
Weight	39.20 lb (17.78 kg)
Max Pressure Tolerance @ 25°C	7.1kgf/cm <sup>2</sup> (101.5psi)
Max Temperature Tolerance	120°C (248°F)
Hardness (Shore)	70A

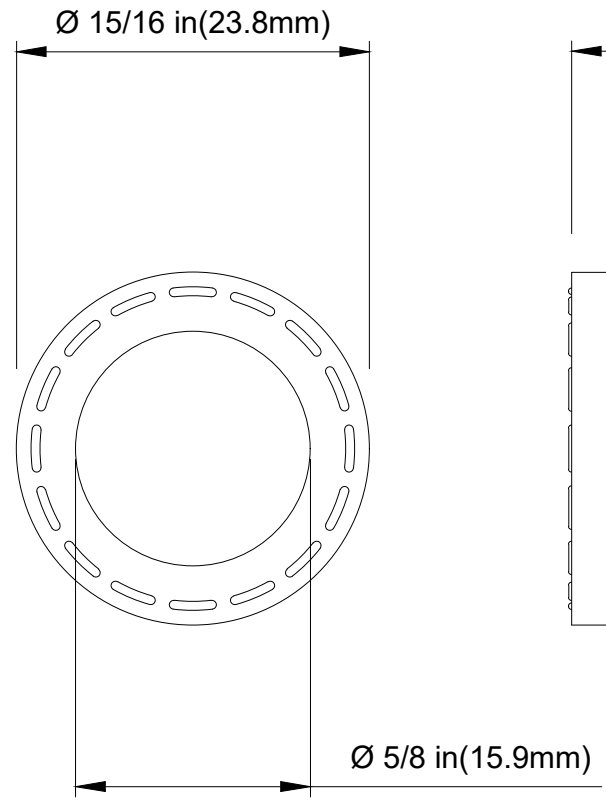

### EPDM thread-reinforced

NO.	DESCRIPTION				MATER'L	QUANTITY	REMARKS
					UNIT	inch	APPAR
					SCALE	N/S	TITLE
DATE	BY	BY	BY	APPRD BY	3RD ANGLE		
2026.05.11	SK.An				CODE NO.	DWG. NO.	