




Koolance black EPDM thread-reinforced hose with 6mm (1/4in) internal diameter, 13mm (1/2in) external diameter. Length 3m / 9.8ft. Bend radius is approximately 30mm (1.18in).


General	
Weight	0.80 lb (0.36 kg)
Max Pressure Tolerance @ 25 °C	7.1kgf/cm2 (101.5psi)
Max Temperature Tolerance	120 °C (248 °F)
Hardness (Shore)	70A

Ø 1/2 in (12.7mm)

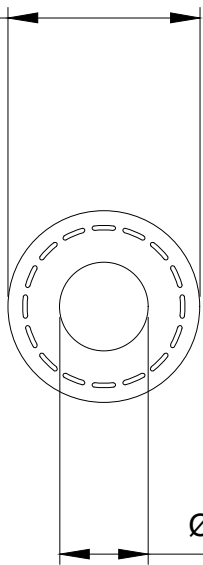

Ø 1/4 in (6.4mm)

LENGTH IS REPRESENTATIVE

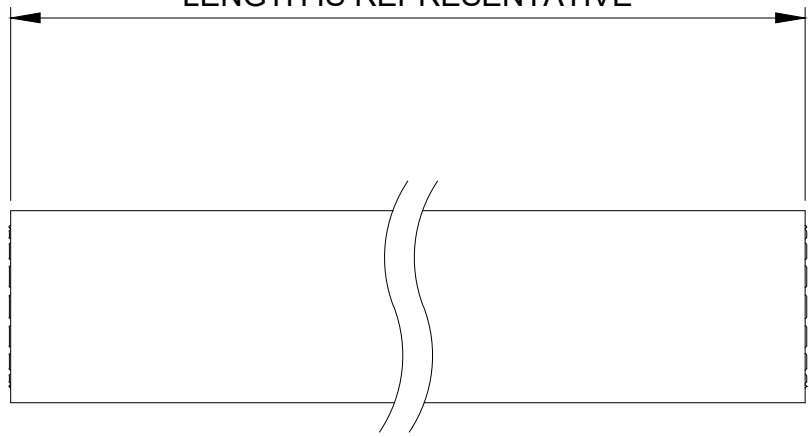

EPDM thread-reinforced

NO.	DESCRIPTION					MATER'L		QUANTITY	REMARKS
						UNIT	inch	APPAR	
						SCALE	N/S	TITLE	HOS-06X13EP-XX
DATE	BY	BY	BY	APPRD BY	3RD ANGLE				
2026.05.11	SK.An				CODE NO.			DWG. NO.	