

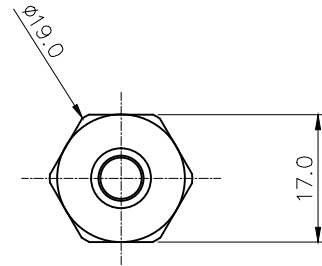


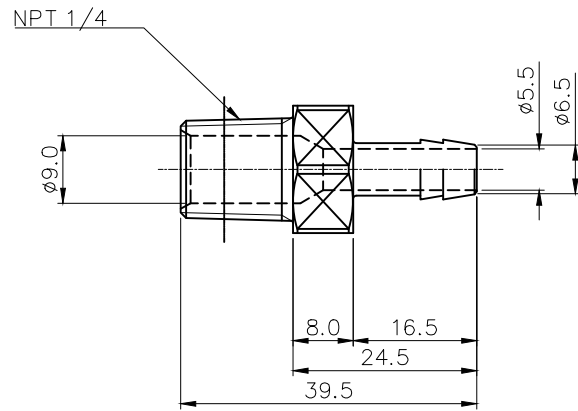

Single hose barb fitting for 1/4in (6mm) ID tubing. 1/4 NPT (tapered) thread. Includes hose clamp for 3/8in (10mm) OD tubing.

General	
Weight	0.03 lb (0.01 kg)
Max Pressure Tolerance @ 25 °C	15kgf/cm2 (213.4psi)
Max Temperature Tolerance	120 °C (248 °F)
Wetted Materials	SUS 316, EPDM

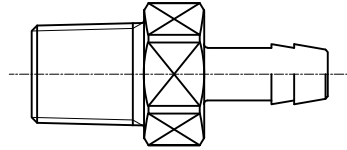

REV	DATE	CONTENTS	REVD BY	CHKD BY	APPD BY
REVISION					

NO.	DESCRIPTION			MATER'L	QUANTITY	REMARKS
KOLANCE	UNIT	MM	SCALE	N/S	ITEM	FIT-V06N14-SS
	DATE	BY	BY	BY	APPRO BY	TITLE
	ys.shin					NPT 1/4 6mm 호스바브 노즐
						3RD ANGLE
						CODE NO.
						DWG. NO.
						PAGE