



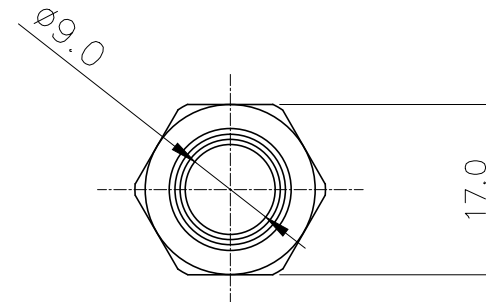

Single hose barb fitting for 3/8in (10mm) ID tubing. 1/4 NPT (tapered) thread. Hose clamp for 1/2in (13mm) OD included.

| General                        |                             |
|--------------------------------|-----------------------------|
| Weight                         | 0.03 lb (0.01 kg)           |
| Max Pressure Tolerance @ 25° C | 15kgf/cm2 (213.4psi)        |
| Max Temperature Tolerance      | 120° C (248° F)             |
| Wetted Materials               | Brass, Nickel Plating, EPDM |

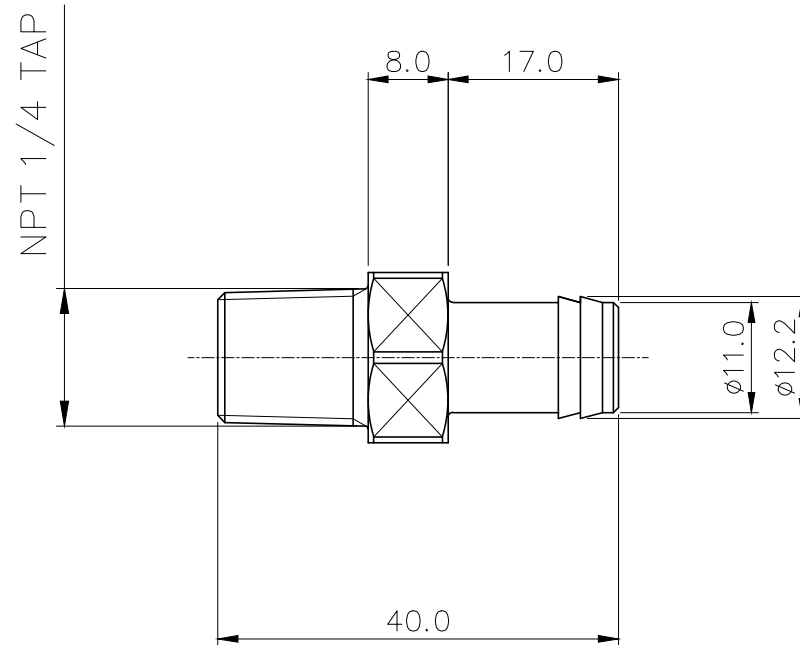

|          |      |          |         |         |         |
|----------|------|----------|---------|---------|---------|
|          |      |          |         |         |         |
|          |      |          |         |         |         |
| REV      | DATE | CONTENTS | REVD BY | CHKD BY | APPD BY |
| REVISION |      |          |         |         |         |

|                 |  |             |    |    |          |    |                  |         |
|-----------------|--|-------------|----|----|----------|----|------------------|---------|
| NO.             |  | DESCRIPTION |    |    | MATER'L  |    | QUANTITY         | REMARKS |
| <b>KOOLANCE</b> |  | SCALE       |    |    | UNIT     | MM | APPAR FIT-V10N14 |         |
|                 |  |             |    |    | N/S      |    | TITLE            |         |
| DATE            |  | BY          | BY | BY | APPRD BY |    | 3RD ANGLE        |         |
|                 |  | S.J.LEE     |    |    |          |    | Ass'y            |         |
|                 |  |             |    |    | REF. NO. |    | DWG. NO.         |         |
|                 |  |             |    |    |          |    |                  |         |