



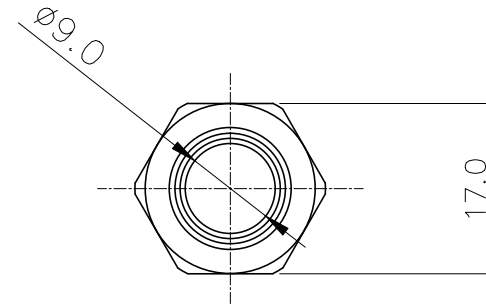

Single hose barb fitting for 3/8in (10mm) ID tubing. 1/4 NPT (tapered) thread. Hose clamp for 1/2in (13mm) OD included.

General	
Weight	0.03 lb (0.01 kg)
Max Pressure Tolerance @ 25° C	15kgf/cm2 (213.4psi)
Max Temperature Tolerance	120° C (248° F)
Wetted Materials	Brass, Nickel Plating, EPDM

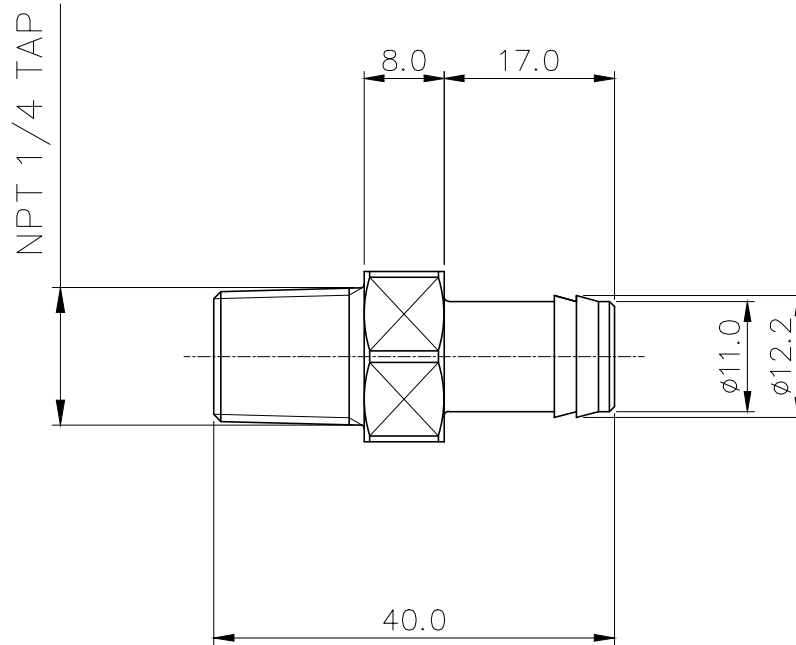

REV	DATE	CONTENTS	REVD BY	CHKD BY	APPD BY
REVISION					

NO.		DESCRIPTION			MATER'L		QUANTITY	REMARKS
<b>KOOLANCE</b>					UNIT	MM	APPAR FIT-V10N14	
					SCALE	N/S	TITLE	
DATE	BY	BY	BY	APPRD BY	3RD ANGLE			Ass'y
	S.J.LEE				REF. NO.			DWG. NO.