





Single hose barb fitting for 3/8in (10mm) ID tubing. G 1/4 BSPP (parallel) thread. Hose clamp included for 1/2in (13mm) OD tubing.

General	
Weight	0.03 lb (0.01 kg)
Fitting Thread	G 1/4 BSPP
Max Pressure Tolerance @ 25° C	15kgf/cm2 (213.4psi)
Max Temperature Tolerance	120° C (248° F)
Wetted Materials	Brass, Nickel Plating, EPDM

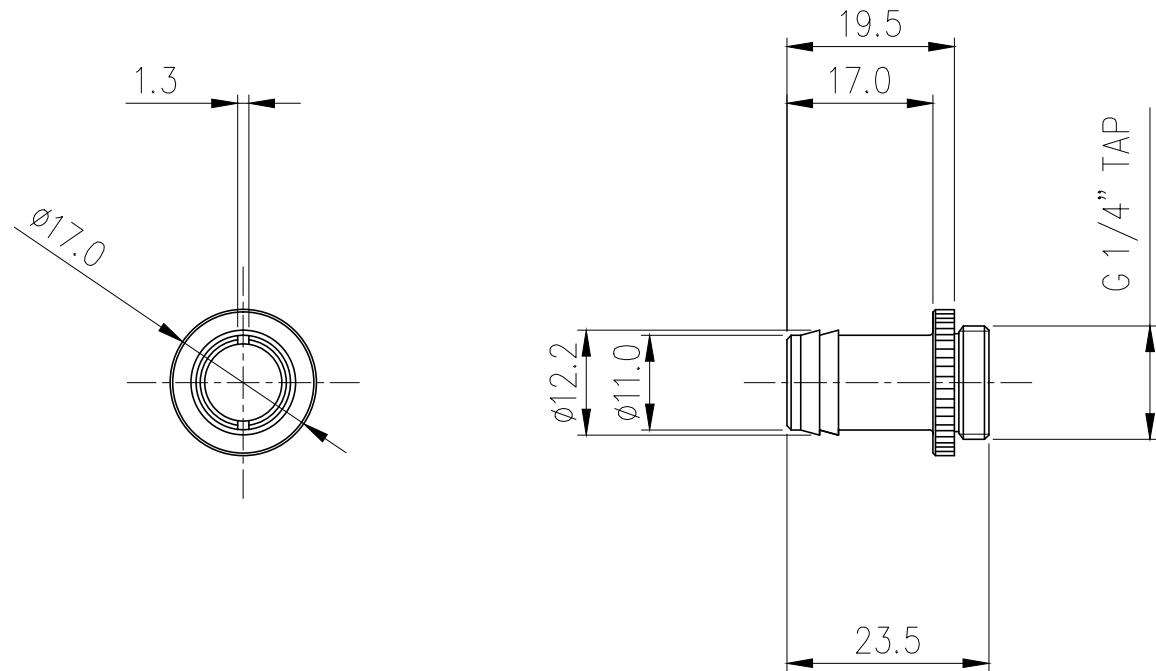

NO.		DESCRIPTION				MATER'L		QUANTITY		REMARKS	
						UNIT		MM		APPAR NZL-V10B(-BK)	
						SCALE		N/S		TITLE Ass'y	
DATE		BY		BY		BY		APPRO BY			
04/21/2017		S.J.LEE								CODE NO.	
										DWG. NO.	